

Single Pole Devices and Temporary Power

150A, 600V AC/DC

Female Plugs

Features

- Extra Long non-conductive inner sleeve
- Turn and Lock Symbol aids in the mating of devices
- Easily Identifiable Cable with cut off points for secure fit

Ordering Information

| Description | Device Color | UPC Number | Catalog Number |
|---|--------------|--------------|----------------|
| 150A, thermoplastic elastomer, cable size #8 - #2 AWG | Red | 783585458397 | HBL15FR |

Listings

UL and cUL Listed
UL Enclosure Types 3R, 4X, 12
National Electric Code (NEC), ANSI/NFPA 70

Specifications


| | |
|--------------------------|-------------------------------|
| Base Compound | Thermoplastic Elastomer (TPE) |
| Contact Material | Brass |
| Retaining Screw Material | Nylon |

Performance

| Electrical | |
|-----------------|--------------------|
| Amperage Rating | 150A Maximum |
| Voltage Rating | 600V AC/DC Maximum |

| Mechanical | |
|------------------------|--|
| Product Identification | Ratings are a permanent part of device |
| Terminal Accommodation | #8 to #2 AWG |

HUBBELL

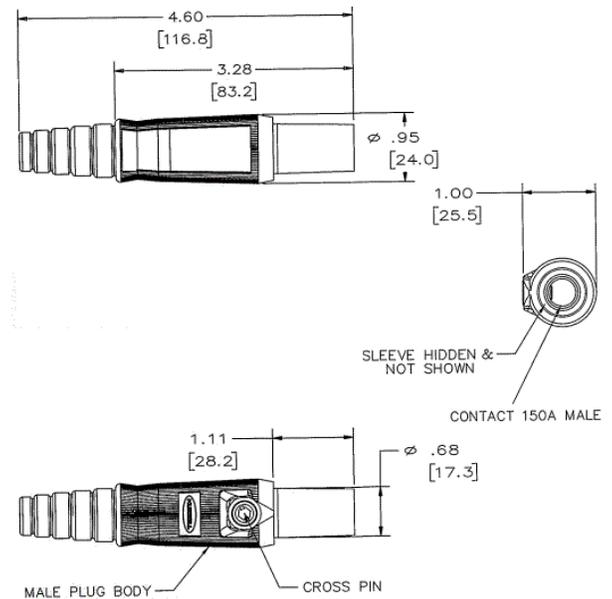

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

