

Twist-Lock® Devices  
20A, 125V AC, 2 Pole, 3 Wire Grounding  
Single Flush Receptacle

HUBBELL

Features

- High-impact, abuse-resistant nylon face
- Accepts ring terminals
- Face color coding by voltage facilitates locating and mating of proper devices
- All-brass mounting and grounding system provides a lower resistance ground path and greater resistance to corrosion than steel mounting systems

Ordering Information

| Description                           | Device Color | UPC          | Catalog Number |
|---------------------------------------|--------------|--------------|----------------|
| Nylon face, ring terminal connection. | Black        | 783585234038 | HBL2310RT      |

Listings

Listed to UL 498  
Fed.Spec. W-C-596  
Certified to CSA C22.2 No.42

Specifications


|                 |                                                |
|-----------------|------------------------------------------------|
| Face            | Nylon                                          |
| Base            | Glass-Reinforced thermoplastic polyester (RTP) |
| Contacts        | Brass                                          |
| Terminal Screws | #10 - 32 Brass                                 |
| Mounting Strap  | Brass                                          |

Performance

|                      |                                                          |
|----------------------|----------------------------------------------------------|
| <b>Electrical</b>    |                                                          |
| Current Interrupting | Certified for current interrupting at full rated current |
| Dielectric Voltage   | Withstands 2,000V minimum                                |

|                         |                                                      |
|-------------------------|------------------------------------------------------|
| <b>Mechanical</b>       |                                                      |
| Terminal Accommodation  | #16 AWG - #8 AWG solid or stranded copper wire only. |
| Terminal Identification | Terminals identified in accordance with UL 498       |

|                        |                                                     |
|------------------------|-----------------------------------------------------|
| <b>Environmental</b>   |                                                     |
| Flammability           | V2 or better per UL94/CSA 22.2 No.0.17              |
| Moisture Resistance    | IP20 Suitability                                    |
| Operating Temperatures | Maximum Continuous 75°C; Minimum -40°C (w/o impact) |

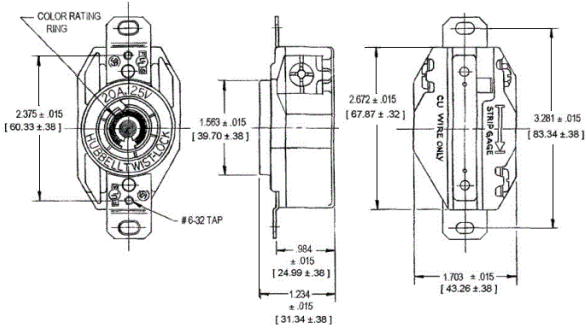

Accessories

|                                 |               |
|---------------------------------|---------------|
| Plug                            | HBL2311       |
| Wallplate or Weatherproof Cover | 1.60" Opening |

Resources

Customer Use Drawing  
[eCatalog](#)

