

HUBBELL
Wiring Device-Kellems

**Straight Blade Devices, 4-Plex Receptacle,
Commercial Grade, Surge Protected, 20A
125V, 2-Pole 3-Wire Grounding, 5-20R, Red**

By Hubbell Wiring Device-Kellems
Catalog # [HBL420HRS](#)

Straight Blade Devices, 4-Plex Receptacle, Commercial Grade,
Surge Protected, 20A 125V, 2-Pole 3-Wire Grounding, 5-20R, Red

Features

- Mounts directly to 4-inch square box
- Heavy duty, impact resistant housing
- Removable knockouts for mounting
- Heavy duty, triple wipe, brass power and ground contacts

Application

4-Plex Hospital Grade

Performance

Electrical - Frequency - 60Hz, Electrical - Protection Modes - Normal and Common Modes, Electrical - Response Time - Approximately 5 ns, Electrical - Transient Suppression - Peak Energy (10 X 100 μ s), Peak Current (8 X 20 μ s), Electrical - Voltage - 20V AC + 10% - 15%, Environmental - Flammability - UL 94V-2, Environmental - Operating Temperature - -40°F to 140°F (-40°C to 60°C)

Specifications


Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	No
Industry Standard(s)	<ul style="list-style-type: none">• Certified to CSA 22.2, No. 42 File 285• Listed to UL Standard 498 File E2186
Nema Rating	5-20R

Conductor

Number Of Wires	3-Wire Grounding
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

Current

Current Rating	20 A
Amperage Rating	20 A

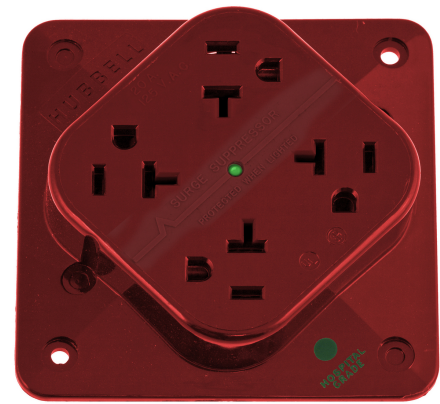

Voltage Rating Description	125 V
Phase	Single Phase
Current / Amperage Rating	20 A
Connectivity	Back Wired Screw Terminals
Wattage	2500
Voltage Rating	125 V

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

General

Series	Hospital Grade
OEM Brand Name	Hubbell Wiring Device-Kellems
Color	Red
Item Type	4-PLEX
Material - Mounting Hardware	Screw Mounting
Type	4-Plex
Material	Polycarbonate
Specifications	<ul style="list-style-type: none">• Base Material - Lexan®• Contact Design - Triple Wipe• Face Material - Lexan®• Mounting Screws - Brass• Power Contacts - .032 in. (.8) Brass
UPC	783585252353

Logistics

Carton Quantity	5
-----------------	---

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)
- [Installation Manual \[Spanish, French, English\]](#)