

# Twist-Lock® Devices 15A, 125V, 2 Pole, 3 Wire Grounding Receptacle

# HUBBELL

## Features

- Reinforced thermoplastic construction
- Single piece, all brass contacts
- Single point break-off tabs
- Mounting strap tabs lock the body and base together

## Ordering Information

Description	Device Color	UPC	Catalog Number
Duplex, ring terminal connection	Brown	783585318554	HBL4700RT

## Listings

Listed to UL 498  
Fed. Spec. W-C-596  
Certified to CSA C22.2 No.42

## Specifications

Face	RTP
Base	RTP
Contacts	Brass
Ground Contact	Brass
Terminal Screws	Brass

## Performance

### Electrical

Current Interrupting Certified for current interrupting at full rated current  
Dielectric Voltage Withstands 2,000V minimum


### Mechanical

Terminal Accommodation #18 AWG - #10 AWG solid or stranded copper wire only.

Terminal Identification Terminals identified in accordance with UL 498

### Environmental

Flammability HB or better per UL94/CSA 22.2 No.0.17  
Operating Temperatures Maximum Continuous 75°C; Minimum -40°C (w/o impact)

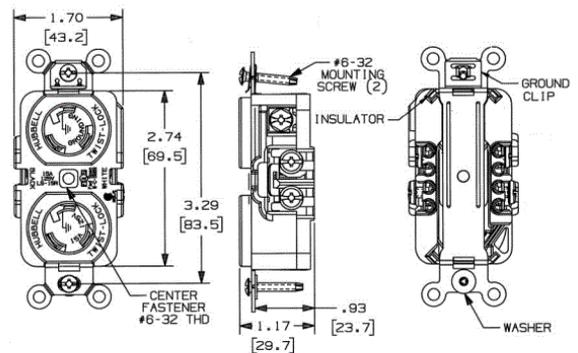

## Accessories

Plug HBL4720C  
Wallplate or Weatherproof Cover Duplex Opening

## Resources

Customer Use Drawing  
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

