


**Straight Blade Devices, Receptacles,  
Weather-Resistant Duplex, Industrial Grade,  
15A 125V, 2-Pole 3-Wire Grounding, 5-15R,  
Gray, Single Pack**

By Hubbell Wiring Device-Kellems  
Catalog # [HBL5262GYWR](#)

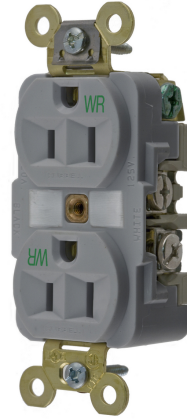

Straight Blade Receptacle Weather-Resistant Duplex 15A

**Features**

- Weather-resistance complies with national electrical code requirements
- Finder Groove Face
- One-piece brass integral ground strap
- Deep body design with circuit ID face

**Application**

Extra Heavy Duty Specification Grade

**Performance**

Electrical - Current Interrupting - Certified for current interrupting at full rated current, Electrical - Dielectric Voltage - Withstands 2,000V minimum, Environmental - Flammability - Top: UL 94V-2, Base: UL 94V-0, Environmental - Operating Temperatures - Maximum continuous 75°C, minimum -40°C (w/o impact), Mechanical - Product Identification - Ratings are a permanent part of the device, Mechanical - Terminal Accommodation - #14-#10 AWG copper stranded or solid conductor only, Mechanical - Terminal Identification - Terminals identified in accordance with UL 498 and CSA

**Specifications**

Environmental Conditions	Weather Resistant
EU RoHS Indicator	No
Standards - RoHS Compliance Status	CM
Industry Standard(s)	<ul style="list-style-type: none"> <li>• Certified to CSA 22.2, No. 42 File 285</li> <li>• Fed. Spec. WC596</li> <li>• NEMA® WD-6 Compliant</li> <li>• UL Listed to UL498 File No. E2186</li> </ul>
Nema Rating	5-15R

**Conductor**

Number Of Wires	3-Wire
Wire Size	#14 AWG to #10 AWG
Number Of Poles	2-Pole

**Current**

Dielectric Strength	Withstands 2,000V minimum
Current Rating	15 A

Amperage Rating	15 A
Voltage Rating Description	125 V
Phase	Single Phase
Current / Amperage Rating	15 A
Connectivity	Back and Side Wired
Wattage	1875 W
Voltage Rating	125 VAC

**Dimensions**

Display Size	Standard Sized Product
Length	3.28 in
Width	1.65 in
Weight	0.25 lb.
Height	1.19 in
Dimensions	3.28 in x 1.65 in x 1.19 in

**General**

Series	Extra Heavy Duty
Style	Finder Groove Face
Color	Gray
Item Type	Traditional Duplex
Material - Mounting Hardware	Screw Mounting
Type	Weather Resistant
Specifications	<ul style="list-style-type: none"> <li>• Automatic Self-grounding Clip - Stainless steel</li> <li>• Base - PBT</li> <li>• By-Pass Power Contacts - .036". (.9) Brass</li> <li>• Clamp - Brass</li> <li>• Contacts - 0.031" (0.8) Brass</li> <li>• Face - Nylon</li> <li>• Mounting Screws - Stainless Steel</li> <li>• Terminal Screws - Brass</li> </ul>
UPC	783585320519

**Logistics**

Carton Quantity	10
-----------------	----

**Operational**

Operating Temperature	Maximum continuous 75°C and minimum -40°C without Impact
Horsepower - Maximum	0.5



A Hubbell brand