

Load:Logic® Load Control Receptacles

- Designed for Automatic Receptacle (plug load) Control
- Duplex controlled face and downstream control
- Low voltage wire control
- Tamper Resistant... NOT Plug Resistant®

Description	Device Color	UPC Number	Catalog Number
Decorator face, back wired	Light Almond	783585427744	HBL5262LC2LA


cULus 498B SA UL File No. E481574
 Fed. Spec. WC596G
 Complies with: NEC Section 406.3 (E), ASHRAE 90.1 Section 8.4.2, California Title 24
 Article 130.5(d)
 NEMA WD-6 Compliant

Face	Nylon
Base	Nylon
Power Contacts	0.031in (0.8) Brass
Wire Clamp	0.062in (1.6) Steel-Nickel Finish
Mounting Strap	0.047in (1.2) Brass
Terminal Screws	#8-32 Brass, Multiple Drive
Self -Grounding Staple	Stainless Steel
Mounting Screws	Zinc-Plated Steel

Electrical	
Current Interrupting	Certified for current interrupting at full rated current

Mechanical	
Product Identification	Ratings are a permanent part of the device
Terminal Accomodation	#14-10 AWG stranded or solid copper conductor only
Terminal Identification	Terminals identified in accordance with UL498 and CSA (Brass, White, Green)

Flammability	UL94V-2
Operating Location	Indoor Use Only
Operating Temperature	0° to 40°C (32° to 104°F) Relative Humidity (non-condensing) 0% to 95% (w/o impact)

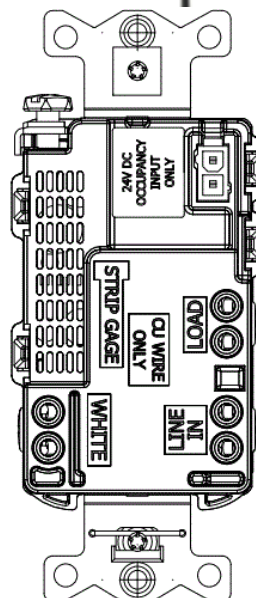

Wallplate, Decorator Opening, Nylon	NP26LA
Wallplate, Decorator Opening, Stainless Steel	SS26

Customer Use Drawing
eCatalog
Installation Instructions



Wiring Device-Kellems