

Straight Blade Devices

15A, 125V, 2 Pole, 3 Wire Grounding

Load:Logic® Load Control Receptacles



- Features
- Designed for Automatic Receptacle (plug load) Control
  - Duplex controlled face and downstream control
  - Clear Connect/Vive Enabled wireless control
  - Tamper Resistant... NOT Plug Resistant®

Ordering Information

| Description                | Device Color | UPC Number   | Catalog Number |
|----------------------------|--------------|--------------|----------------|
| Decorator face, back wired | Brown        | 783585402048 | HBL5262RFC2    |

Listings


cULus 498B SA UL File No. E481574  
Fed. Spec. WC596G  
Complies with:NEC Section 406.3 (E), ASHRAE 90.1 Section 8.4.2,California Title 24  
Artcile 130.5(d)  
NEMA WD-6 Compliant

Specifications

|                        |                                   |
|------------------------|-----------------------------------|
| Face                   | Nylon                             |
| Base                   | Nylon                             |
| Power Contacts         | 0.031in (0.8) Brass               |
| Wire Clamp             | 0.062in (1.6) Steel-Nickel Finish |
| Mounting Strap         | 0.047in (1.2) Brass               |
| Terminal Screws        | #8-32 Brass, Multiple Drive       |
| Self -Grounding Staple | Stainless Steel                   |
| Mounting Screws        | Zinc-Plated Steel                 |

Performance

|                         |                                                                                     |
|-------------------------|-------------------------------------------------------------------------------------|
| <b>Electrical</b>       |                                                                                     |
| Current Interrupting    | Certified for current interrupting at full rated current                            |
| Dielectric Voltage      | Withstands 2,000V minimum                                                           |
| <b>Mechanical</b>       |                                                                                     |
| Product Identification  | Ratings are a permanent part of the device                                          |
| Terminal Accomodation   | #14-10 AWG stranded or solid copper conductor only                                  |
| Terminal Identification | Terminals identified in accordance with UL498 and CSA (Brass, White, Green)         |
| <b>Environmental</b>    |                                                                                     |
| Flammabilty             | UL94V-2                                                                             |
| Operating Location      | Indoor Use Only                                                                     |
| Operating Temperature   | 0° to 40°C (32° to 104°F) Relative Humidity (non-condensing) 0% to 95% (w/o impact) |

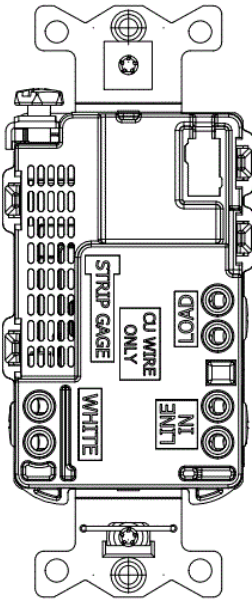

Complementary Products

|                                               |      |
|-----------------------------------------------|------|
| Wallplate, Decorator Opening, Nylon           | NP26 |
| Wallplate, Decorator Opening, Stainless Steel | SS26 |

Online Resources

Customer Use Drawing  
eCatalog  
Installation Instructions

