

Temporary Power
Temporary Industrial Lighting
LED Worklights



Features

- Easy, portable LED light fixture
- 120% LED efficiency
- Wire cage and Polycarbonate design for durability

Ordering Information

Description	UPC Number	Catalog Number
High Bay LED light with wire guard	783585569031	HBLLEDHB60

Listings

UL Listed


Specifications

Light Type	LED
Plug Type	NEMA 5-15P
Connector Type	NEMA 5-15R
Plug Length	5 Feet
Supply Cord	16/3 SJTW
Light Output	7,200 Lumens
Included	Hanging Hook

Performance

Electrical	
Input Current (A)	1
Input Power (W)	60
Lamp Life	50,000 Hours
Output	120 lumens/watt

Mechanical	
Cord	18/2 18 AWG
Cord Length	5 ft.
Enclosure	Poly Carbonate
Lens	Poly Carbonate
Lens Gasket	Silicon
Mounting Bracket/Hanging Hook	Steel

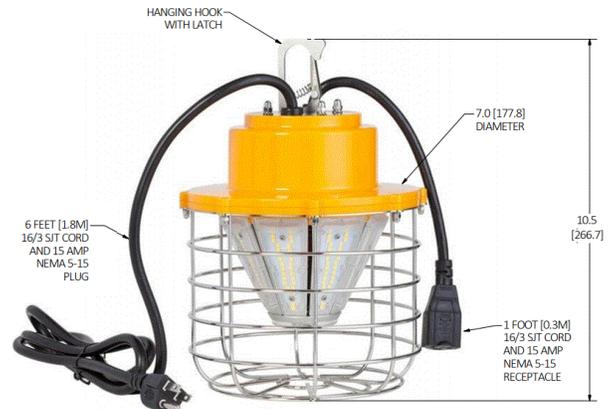

Online Resources

- Customer Use Drawing
- eCatalog
- Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

