

HI-Impact

Category 6 Patch Cords

Standard Cat 6 RJ45 on Both Ends



- Features
- High-Performance Category 6
 - IP67 and IP66 Rated for Dust and Liquids
 - Durable, Rugged Construction
 - Intuitive, Quick Action Mating



Ordering Information


Description	Color	Catalog Number	UPC
HI-Impact Standard Cat 6 RJ45 on Both Ends, 25 feet	Black	HI625AA	662620856186

- Listings
- UL and cUL Listed
 - TIA-568-C.2 Category 6 Component

Performance

Electrical	Qualified to 150% of 802.3bt PoE Current Level
Mechanical	Vibration: 5g (operational) 10-500Hz Mating Cycle: 750 minimum
Environmental	Ingress Protection: IP67 and IP66 (dust/water) HI-Impact Housing Temperature Range: -25°C to 70°C Corrosion: Resistant to most common chemicals, oils and cleaning agents UV Resistant Housing

- Applications
- IEEE 802.3ab 1000GBASE-T
 - IEEE 802.3bt 4PPoE Power over Ethernet
 - TIA TSB-155 10GbE Over 55 Meters
 - Backward compatible with Cat 5E hardware and applications

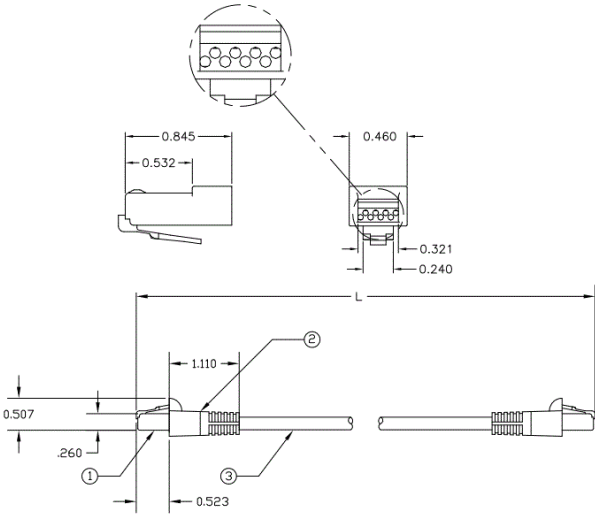

- Online Resources
- Customer Use Drawing
 - eCatalog