

Field Attachable Micro-Quick Control
Connectors, Female Straight, 3 Wire,
Insulation Displacement

By Hubbell Wiring Device-Kellems
Catalog # [MCMS13IDCL](#)

Field Attachable Micro-Quick Control Connectors, Female
Straight, 3 Wire, Insulation Displacement

Features

- Strain relief bushing protects terminations
- Wire Guide for virtually toolless termination
- Insulation displacement contacts are made of Copper Alloy

Application

Quick Connect/Disconnect Signal and Control

Specifications


Industry Standard(s)	• CSA Certified, C22.2 No. 182.3 and CSA C22.2 No. 94.2-07 • UL 2238 and UL50E, File No. E192071
EU RoHS Indicator	Yes

Conductor

Conductor Type	Copper
Number Of Conductors	3-Pole

Dimensions

Diameter Live Part	.59"
--------------------	------

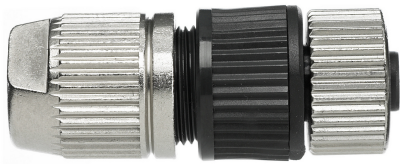

General

OEM Brand Name	Hubbell Wiring Device-Kellems
Specifications	• Contact Materials - Copper Alloy • Contact Plating - Tin over Nickel • Housing - Polyester Elastomer, Black • Strain Relief Bushing - Neoprene, Black • Wire Guide - Nylon 6/6, Gray
UPC	783585226750
Color	Black

Logistics

Carton Quantity	25
-----------------	----

Operational

Temperature Rating	-20 Deg C to 105 Deg C
--------------------	------------------------

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[Spanish, French, English\]](#)