


Plates, Wall Phone, 6-Position 4- Conductor, 110 Block, Electric Ivory

By Hubbell Wiring Device-Kellems
Catalog # [NS7211](#)

Plates, Wall Phone, 6-Position 4- Conductor, 110 Block, Electric Ivory

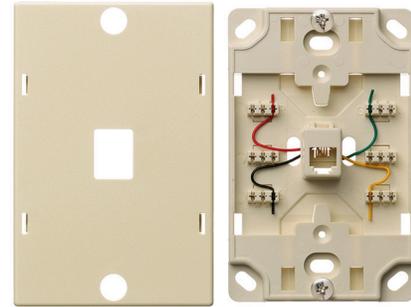

Features

- Meets FCC part 68
- Available in high impact-resistant thermoplastic or stainless steel

Application

Communications

Specifications

Industry Standard(s)	UL Listed
EU RoHS Indicator	Yes

Current

Connectivity	110 Punch Down
Contact Resistance	Per TIA
Insertion Loss	Per TIA

Dimensions

Size	Standard
------	----------

General

Material - Mounting Hardware	Screw Mounting
Type	Telephone Jack
Material	Nylon
Specifications	Device Type - 6-Position, 4-Conductor
UPC	883778502606
Color	Ivory

Logistics

Carton Quantity	10
-----------------	----

Operational

Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
--------------------	--

Product Assets

[Catalog \[English\]](#)