


## Plates, Wall Phone, 6-Position 4- Conductor, 110 Block, White

By Hubbell Wiring Device-Kellems  
Catalog # [NS721W](#)

Plates, Wall Phone, 6-Position 4- Conductor, 110 Block, White

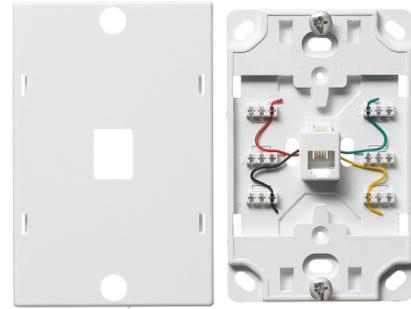

### Features

- Meets FCC part 68
- Available in high impact-resistant thermoplastic or stainless steel

### Application

Communications

### Specifications

Industry Standard(s)	UL Listed
EU RoHS Indicator	Yes

### Current

Connectivity	110 Punch Down
Contact Resistance	Per TIA
Insertion Loss	Per TIA

### Dimensions

Size	Standard
------	----------

### General

Material - Mounting Hardware	Screw Mounting
Type	Telephone Jack
Material	Nylon
Specifications	Device Type - 6-Position, 4-Conductor
UPC	883778502613
Color	White

### Logistics

Carton Quantity	10
-----------------	----

### Operational

Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
--------------------	--

### Product Assets

[Catalog \[English\]](#)