

## Signal And Control, Linkosity, Cordset, Female, Double End, 90 Degree, 3-Wire, 10A 600V AC, PA Wire Code, 5' Length, Stainless Hex Nuts

By Hubbell Wiring Device-Kellems  
Catalog # [PG1003PA005S](#)

Signal And Control, Linkosity, Cordset, Female, Double End, 90 Degree, 3-Wire, 10A 600V AC, PA Wire Code, 5' Length, Stainless Hex Nuts

### Features

- Linkosity
- Cordset
- Female
- Double End

### Application

Quick Connect/Disconnect Signal and Control

### Specifications


EU RoHS Indicator Yes

### Conductor

Conductor Type Copper  
Strands Multi  
Number Of Conductors 3-Pole

### Current

Amperage Rating 10 A

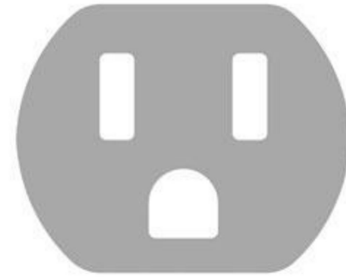

**Oh No!**  
IMAGE COMING SOON

Voltage Rating 600V kV

### Dimensions

Outside Diameter 0.71

### General

Plug Type Linkosity  
OEM Brand Name Hubbell Wiring Device-Kellems  
UPC 783585184845  
Color Gray

### Logistics

Carton Quantity 10

### Operational

Temperature Rating -20 Deg C to 105 Deg C

### Product Assets

[Catalog \[English\]](#)  
[Installation Manual \[English\]](#)