

Signal And Control, Linkosity, Cordset, Female, Double End, 90 Degree, 3-Wire, 10A 600V AC, PB Wire Code, 10' Length, Stainless Hex Nuts

By Hubbell Wiring Device-Kellems
Catalog # [PG1003PB010S](#)

Signal And Control, Linkosity, Cordset, Female, Double End, 90 Degree, 3-Wire, 10A 600V AC, PB Wire Code, 10' Length, Stainless Hex Nuts

Features

- Linkosity
- Cordset
- Female
- Double End

Application

Quick Connect/Disconnect Signal and Control

Specifications


EU RoHS Indicator Yes

Conductor

Conductor Type Copper
Strands Multi
Number Of Conductors 3-Pole

Current

Amperage Rating 10 A

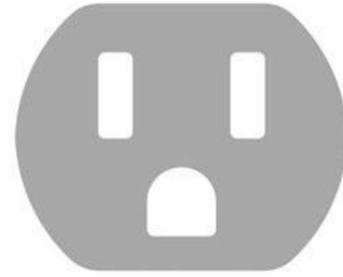

Oh No!
IMAGE COMING SOON

Voltage Rating 600V kV

Dimensions

Outside Diameter 0.71

General

Plug Type Linkosity
OEM Brand Name Hubbell Wiring Device-Kellems
UPC 783585184807
Color Gray

Logistics

Carton Quantity 10

Operational

Temperature Rating -20 Deg C to 105 Deg C

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)