

HUBBELL
Wiring Device-Kellems

**Signal And Control, Linkosity, Cordset,
Female, Double End, 90 Degree, 7-Wire,
10A 600V AC, PE Wire Code, 20' Length**

By Hubbell Wiring Device-Kellems
Catalog # [PG1007PE020](#)

Signal And Control, Linkosity, Cordset, Female, Double End, 90
Degree, 7-Wire, 10A 600V AC, PE Wire Code, 20' Length

Features

- Linkosity
- Cordset
- Female
- Double End

Application

Quick Connect/Disconnect Signal and Control


Specifications

EU RoHS Indicator Yes

Conductor

Conductor Type Copper
Number Of Conductors 7-Pole

Dimensions

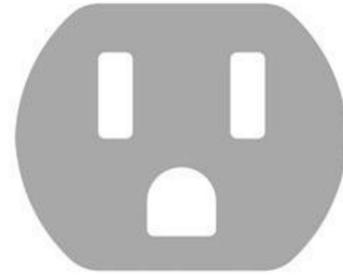

Oh No!
IMAGE COMING SOON

Diameter Live Part .46"

General

Jacket PVC
OEM Brand Name Hubbell Wiring Device-Kellems
UPC 783585454115
Color Gray

Logistics

Carton Quantity 10

Operational

Temperature Rating -20 Deg C to 105 Deg C

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)