


## Linkosity, 20A Single Female Right Angle Cable, 5'

By Hubbell Wiring Device-Kellems  
Catalog # [PG2304PB005](#)

Linkosity, 20A Single Female Right Angle Cable, 5'

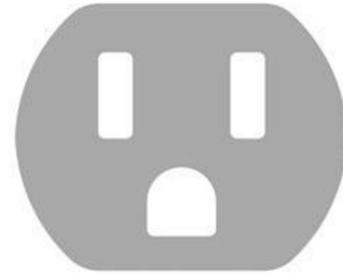

**Oh No!**  
IMAGE COMING SOON

### Features

- Linkosity
- 20A Single Female Right Angle Cable
- 5'

### Application

Quick Connect/Disconnect Signal and Control

### Specifications

EU RoHS Indicator Yes

### Conductor

Conductor Type Copper  
Strands Multi  
Number Of Conductors 4-Pole

### Current

Amperage Rating 20 A  
Voltage Rating 600V kV

### Dimensions

Outside Diameter 0.75

### General

Plug Type Linkosity  
OEM Brand Name Hubbell Wiring Device-Kellems  
UPC 783585116761  
Color Gray

### Logistics

Carton Quantity 10

### Operational

Temperature Rating -20 Deg C to 105 Deg C

### Product Assets

[Catalog \[English\]](#)  
[Installation Manual \[English\]](#)