

LINKOSITY, Female Angled Plug, 4-Pole, 10A, Stainless Steel, 10' Length h

By Hubbell Wiring Device-Kellems
Catalog # [PG3004PB010S](#)

LINKOSITY, Female Angled Plug, 4-Pole, 10A, Stainless Steel, 10'
Length h

Features

- LINKOSITY
- Female Angled Plug
- 4-Pole
- 10A
- Stainless Steel

Application

Quick Connect/Disconnect Signal and Control

Specifications


EU RoHS Indicator Yes

Conductor

Conductor Type Copper
Strands Multi
Number Of Conductors 4-Pole

Current

Amperage Rating 30 A

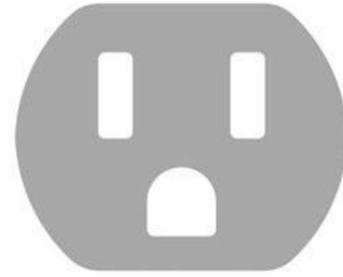

Oh No!
IMAGE COMING SOON

Voltage Rating 600V kV

Dimensions

Outside Diameter 0.75

General

Plug Type Linkosity
OEM Brand Name Hubbell Wiring Device-Kellems
UPC 783585243283
Color Gray

Logistics

Carton Quantity 10

Operational

Temperature Rating -20 Deg C to 105 Deg C

Product Assets

[Catalog \[English\]](#)

[Installation Manual \[English\]](#)