

**Load:Logic<sup>®</sup>**  
**Room Controller**  
**Indoor Photocell**

# HUBBELL

## Features

- Continuously measures daylight levels and sends the information to the controller unit
- Connects to room controller using standard UTP RJ45 patchcords
- Open Loop Control
- Selectabel 0.03 - 6,000 foot candle range



## Ordering Information


Description	Device Color	UPC Number	Catalog Number
Light Sensor - Indoor	White	783585564432	RCDP

## Listings

UL and cUL Listed

## Specifications

Housing	Hard plastic
Dimensions	2" Dia x 1.2" H

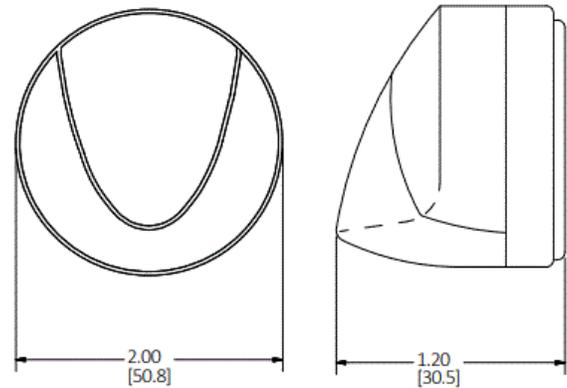

## Performance

### Electrical

Power Supply	24V DC
Range 1	0.3-30 foot candle
Range 2	30-3,000 foot candle

### Environmental

Operating Location	Indoor Use Only
Operating Temperature	0° to 40°C (32° to 104°F) Relative Humidity (non-condensing) 0% to 95%
Range 3	60-6,000 foot candle

## Complementary Products

Patch cord	NSC5EY10PNB
------------	-------------

## Online Resources

Customer Use Drawing  
eCatalog  
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

