

Load:Logic[®]
Room Controller
Specialty Switches - Preset Scenes



- Features**
- Provides manual control of the room controller
 - Connects to room controller using standard UTP RJ45 patchcords
 - Predetermined configuration eliminates setup
 - Default Light Levels: 25, 50, 75, 100%

Ordering Information

Description	Device Color	UPC Number	Catalog Number
6-Button; 4 with Pilot Light, 1 Raise, 1 Lower	Black	783585564715	RCSSCBK

Listings


N/A

Specifications

Housing	Rugged, high-impact, injection-molded plastic
Dimensions	4.2" L x 1.60" W x 1.40" D

Performance

Electrical	
Addressing	8-position rotary switch
Power Requirements	24V DC
Environmental	
Operating Location	Indoor Use Only
Operating Temperature	0° to 40°C (32° to 104°F) Relative Humidity (non-condensing) 0% to 95%

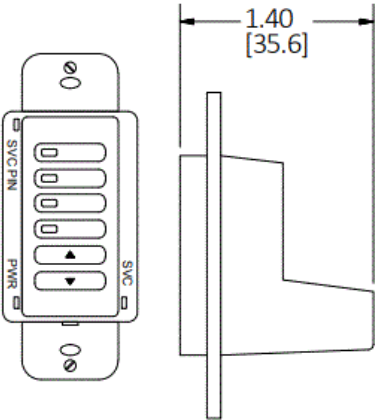

Complementary Products

Wallplate	NPS26BK
Wallplate, Decorator Opening, Snap-on	NPS26BK
Wallplate, Decorator Opening, Stainless Steel	SS26
Patch cord	NSC5EY25PNB

Online Resources

eCatalog

