

Signal and Control, Linkosity, Female Receptacle, 8-Wire, 10A 600V AC, PE Wire Code, 1' Length, Stainless Hex Fittings

By Hubbell Wiring Device-Kellems
Catalog # [RF1008PE001S](#)

Signal and Control, Linkosity, Female Receptacle, 8-Wire, 10A 600V AC, PE Wire Code, 1' Length, Stainless Hex Fittings

Features

- Linkosity8-Wire
- 10A 600V AC

Application

Power and Control Integration

Specifications


EU RoHS Indicator	Yes
Nema Rating	Non-NEMA

Conductor

Conductor Type	Copper
Number Of Conductors	8
Number Of Poles	8-Pole
Conductor Size	#16 AWG

Current

Current / Amperage Rating	10 A
---------------------------	------

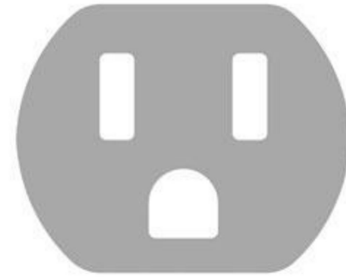

Oh No!
IMAGE COMING SOON

Current Rating	10 A
Amperage Rating	10 A
Wattage	6000
Voltage Rating	600V Max kV

General

Item Type	Female Receptacle
Construction	Fabricated
OEM Brand Name	Hubbell Wiring Device-Kellems
Material	Composite with Stainless Steel Body
UPC	783585243436
Color	Gray

Logistics

Carton Quantity	50
-----------------	----

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)