

## Signal and Control, Linkosity, Female Receptacle, 10-Wire, 10A 600V AC, PE Wire Code, 25' Length

By Hubbell Wiring Device-Kellems  
Catalog # [RF1010PE025](#)

Signal and Control, Linkosity, Female Receptacle, 10-Wire, 10A 600V AC, PE Wire Code, 25' Length

### Features

- Linkosity10-Wire
- 10A 600V AC

### Application

Power and Control Integration

### Specifications


EU RoHS Indicator	Yes
Nema Rating	Non-NEMA

### Conductor

Conductor Type	Copper
Number Of Conductors	10
Number Of Poles	10-Pole
Conductor Size	#16 AWG

### Current

Current / Amperage Rating	10 A
---------------------------	------

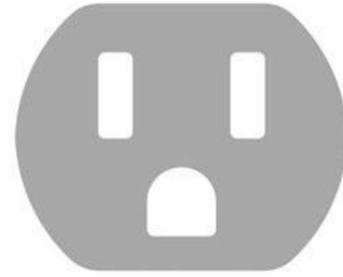

**Oh No!**  
IMAGE COMING SOON

Current Rating	10 A
Amperage Rating	10 A
Wattage	6000
Voltage Rating	600V Max kV

### General

Item Type	Female Receptacle
Construction	Fabricated
OEM Brand Name	Hubbell Wiring Device-Kellems
Material	Composite
UPC	783585093062
Color	Gray

### Logistics

Carton Quantity	5
-----------------	---

### Product Assets

- [Catalog \[English\]](#)
- [Installation Manual \[English\]](#)