

Residential Devices

Medium Base, Pre-Focus, 1000W 250V

Lamp Holders and Sockets

HUBBELL

Ordering Information

Color White	UPC 883778118166	Catalog Number RL3742
-----------------------	----------------------------	---------------------------------

Listings

C/US UL Listed


Specifications

Voltage Rating	250V AC kV
Application	HID Incandescent
Frequency Rating	60 Hz

Performance

Electrical Rating	1500W, 600V Max, 5KV Pulse
-----------------------------	----------------------------

Mechanical Terminal Accommodation	Wire leads: #14 AWG SF-2 (SEW-2) 200° C, 600V glass braid, 12 inch long, stripped 1/2 inch wire
---	---

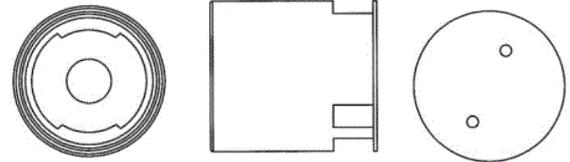

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

