

TradeSelect
15 A, 125 V, 2-Pole, 3-Wire
Single Receptacle, Clock Hanger, Tamper
Resistant



Ordering Information


Color	UPC	Catalog Number
Brass	883778302152	RR151CHBSTR

Listings

UL Listed

Specifications

NEMA Rating	5-15R
Wire Size	#14 AWG to #12 AWG
Wattage	1875
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Clock Hanger Receptacle
Phase	Single Phase

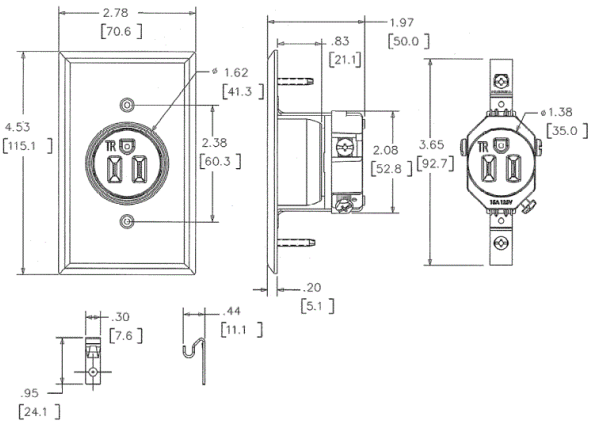

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions

