

TradeSelect

**15 A, 250V kV, 2-Pole, 3-Wire Grounding  
Single Receptacle, Self Grounding**

# HUBBELL

### Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

### Ordering Information

<b>Color</b> Black	<b>UPC</b> 883778300561	<b>Catalog Number</b> RR155BK
-----------------------	----------------------------	----------------------------------

### Specifications


NEMA Rating	6-15R
Wire Size	#14 AWG to #12 AWG
Wattage	3750
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Self Grounding
Phase	Single Phase

### Performance

<b>Environmental</b> Operating temperature	20°C to 60°C
-----------------------------------------------	--------------

### Mechanical

Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only
----------	----------------------------------------------------------------------------------------------

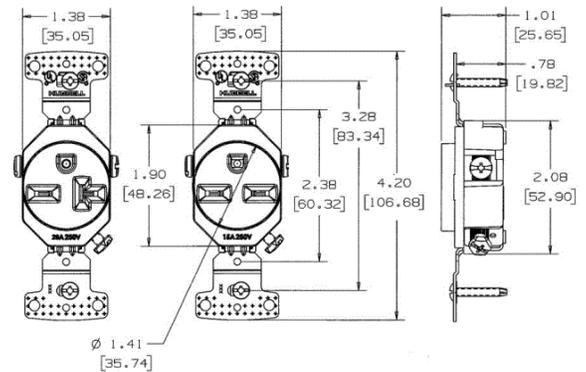

### Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

