

TradeSelect

**15 A, 250V kV, 2-Pole, 3-Wire Grounding
Single Receptacle, Self Grounding**

HUBBELL

Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

Ordering Information

Color Gray	UPC 883778300554	Catalog Number RR155GY
----------------------	----------------------------	----------------------------------


Specifications

NEMA Rating	6-15R
Wire Size	#14 AWG to #12 AWG
Wattage	3750
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Self Grounding
Phase	Single Phase

Performance

Environmental Operating temperature	20°C to 60°C
-----------------------------------------------	--------------

Mechanical Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only
-------------------------------	----------------------------------------------------------------------------------------------

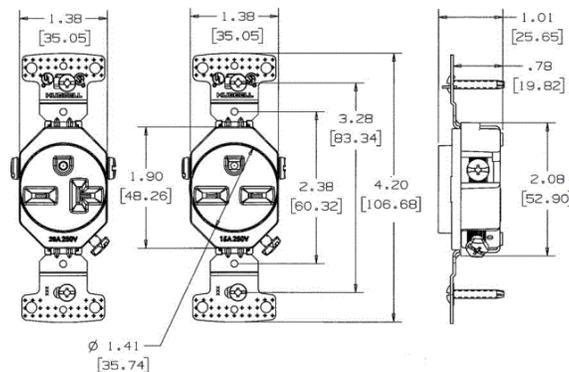

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

