

TradeSelect

15 A, 250V kV, 2-Pole, 3-Wire Grounding

Single Receptacle, Weather Resistant

# HUBBELL

## Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

## Ordering Information

<b>Color</b>	<b>UPC</b>	<b>Catalog Number</b>
Gray	883778302725	RR155GYWR

## Specifications


NEMA Rating	6-15R
Wire Size	#14 AWG to #12 AWG
Wattage	3750
Environmental Conditions	Weather Resistant
Special Features	Weather Resistant- Self Grounding
Phase	Single Phase

## Performance

<b>Environmental</b>	
Operating temperature	20°C to 60°C

## Mechanical

Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only
----------	--

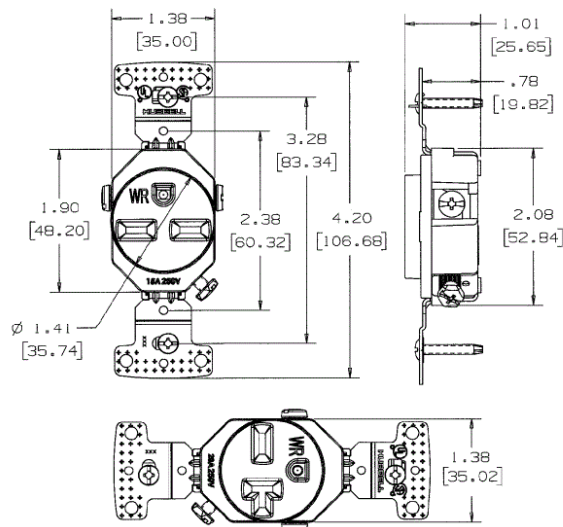

## Online Resources

Customer Sales Drawings  
eCatalog  
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

