


TradeSelect, Straight Blade, Duplex Receptacle, Tamper Resistant, Cut Ears, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Ivory

By Hubbell Wiring Device-Kellems
Catalog # [RR15KITR](#)

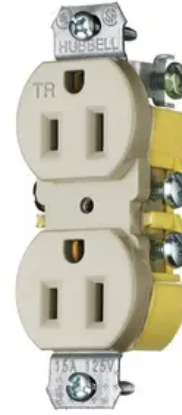

TradeSelect, Straight Blade, Duplex Receptacle, Tamper Resistant, Cut Ears, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Ivory

Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

Application

Residential Receptacles

Performance

- Environmental - Operating temperature - -20°C to 60°C
- Mechanical - Terminal - Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only

General

Catalog Number	RR15KITR
Color	Ivory
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Traditional Duplex
Material	Thermoplastic
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
Specifications	<ul style="list-style-type: none">• Material - Thermoplastic• Number of Poles - 2 Pole• Product Type - Receptacle• Receptacle Type - Duplex
UPC	883778301735

Dimensions

Display Size Standard Sized Product

Electrical Ratings

Amperage Rating	15 A
Connectivity	Eight Push Wire Holes
Current / Amperage Rating	15 A
Current Rating	15 A
Phase	Single Phase
Voltage Rating	125 VAC
Voltage Rating Description	125 VAC
Wattage	1875

Conductor Related

Number Of Wires	3-Wire Grounding
Wire Size	#14 AWG to #12 AWG

Certifications And Compliance

Nema Rating	5-15R
-------------	-------

Logistics

Carton Quantity	100
-----------------	-----

Product Assets

[Catalogs - WDK Catalog Full 2024](#)
[Engineering Drawing - RR15KITR AutoCAD Drawing](#)
[Installation Manuals - WIRING_PD2171_INSTALLINST](#)
[Sales Drawings - WDK_RR15KITR_DRAWING_PDF](#)
[Specifications - RR15KITR Specification Sheet French](#)
[Specifications - RR15KITR Specification Sheet English](#)