



## TradeSelect, Straight Blade, Duplex Receptacle, Tamper Resistant, Cut Ears, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Light Almond

By Bryant  
Catalog # [RR15KLATR](#)

TradeSelect, Straight Blade, Duplex Receptacle, Tamper Resistant, Cut Ears, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Light Almond

### Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

### Application

Residential Receptacles

### Performance

Environmental - Operating temperature - -20°C to 60°C,  
Mechanical - Terminal - Terminal screws accepts up to #12 AWG,  
Push wire designed for #14 AWG solid copper wire only

### Specifications


Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Nema Rating	5-15R

### Conductor

Number Of Wires	3-Wire Grounding
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

### Current

Phase	Single Phase
Current / Amperage Rating	15 A

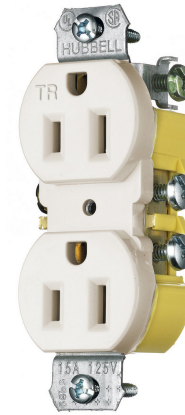

Connectivity	Eight Push Wire Holes
Current Rating	15 A
Amperage Rating	15 A
Voltage Rating Description	125 VAC
Wattage	1875
Voltage Rating	125 VAC

### Dimensions

Display Size	Standard Sized Product
--------------	------------------------

### General

Item Type	Traditional Duplex
Material - Mounting Hardware	Screw Mounting
Material Specifications	Thermoplastic <ul style="list-style-type: none"><li>• Material - Thermoplastic</li><li>• Number of Poles - 2 Pole</li><li>• Product Type - Receptacle</li><li>• Receptacle Type - Duplex</li></ul>
UPC	883778301742
Color	Light Almond

### Logistics

Carton Quantity	100
-----------------	-----

### Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)