

TradeSelect

20 A, 125 VAC, 2-Pole, 3-Wire Grounding

Single Receptacle, Clock Hanger, Tamper Resistant

HUBBELL

Ordering Information


Color Brass	UPC 883778302190	Catalog Number RR201CHBSTR
-----------------------	----------------------------	--------------------------------------

Listings

UL Listed

Specifications

NEMA Rating	5-20R
Wire Size	#12 AWG to #10 AWG
Wattage	2500
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Clock Hanger Receptacle
Phase	Single Phase

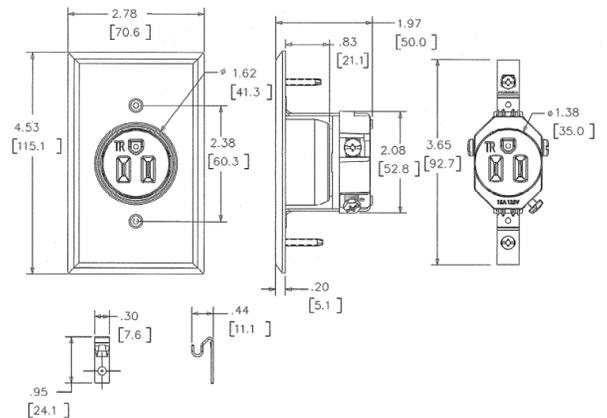

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

