

TradeSelect

20 A, 250V kV, 2-Pole, 3-Wire Grounding

Residential Grade, Receptacles, Single

# HUBBELL

## Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

## Ordering Information

<b>Color</b>	<b>UPC</b>	<b>Catalog Number</b>
Light Almond	883778300653	RR205LA


## Specifications

NEMA Rating	6-20R
Wire Size	#12 AWG to #10 AWG
Wattage	5000
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Self Grounding
Phase	Single Phase

## Performance

<b>Environmental</b>	
Operating temperature	20°C to 60°C

<b>Mechanical</b>	
Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only

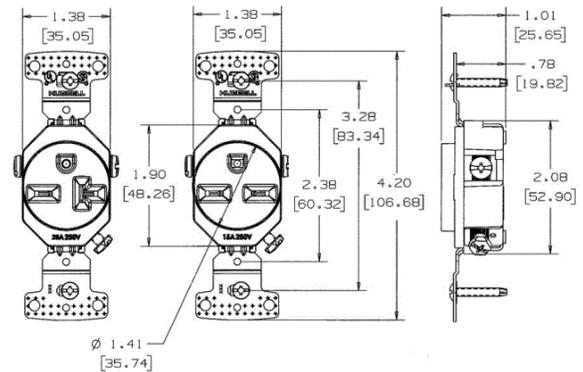

## Online Resources

Customer Sales Drawings  
eCatalog  
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

