

Switches and Lighting Controls

Single Pole, 15A 120/277V AC

Rocker, Marked "On Off"



Features

- Smooth, quiet rocker
- Self-grounding feature is standard
- Ultrasonically welded cover and base
- Residential Grade

Ordering Information

Color	UPC	Catalog Number
Light Almond	883778303753	RSD115LAM

Listings


CSA Certified
Listed to UL Standard 20

Performance

Electrical	
Dielectric voltage	Withstands 1,500V AC minimum for 1 minute
Endurance	30,000 cycles minimum
Max. working voltage	120V
Overload	1.5 times rating

Mechanical	
Terminal accommodation	Back and side wire: #14 AWG min. - #12 AWG max. solid and stranded copper wire only; push wire: #14 AWG solid copper wire only

Environmental	
Flammability	UL V-0
Operating Temperatures	Maximum continuous 60°C; minimum -20°C (without impact)

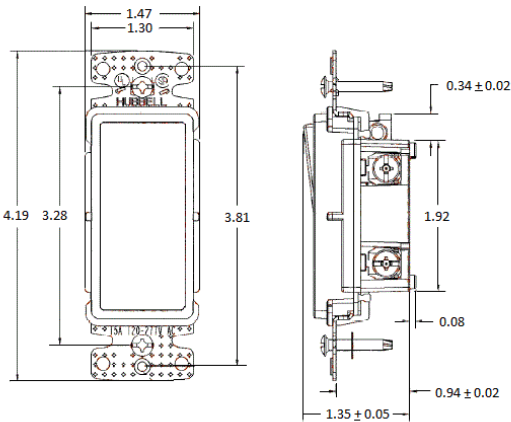

Online Resources

Customer Sales Drawings
eCatalog

