

## Switches and Lighting Controls

### Four Way, 15A 120/277V AC

### Decorator Switch

#### Features

- Smooth, quiet rocker
- Self-grounding feature is standard
- Ultrasonically welded cover and base
- Residential Grade

#### Ordering Information

UPC                      Catalog Number  
883778101458      RSD415GY

#### Listings

CSA Certified  
UL Listed E3896

#### Performance

##### Electrical

Dielectric voltage                      Withstands 1,500V AC minimum for 1 minute  
Endurance                                      30,000 cycles minimum  
Max. working voltage                      120V  
Overload                                        1.5 times rating


##### Mechanical

Terminal accommodation                      Back and side wire: #14 AWG min. - #12 AWG  
max. solid and stranded copper wire only; push  
wire: #14 AWG solid copper wire only

##### Environmental

Flammability                                      UL V-0  
Operating Temperatures                      Maximum continuous 60°C; minimum -20°C  
(without impact)

# HUBBELL

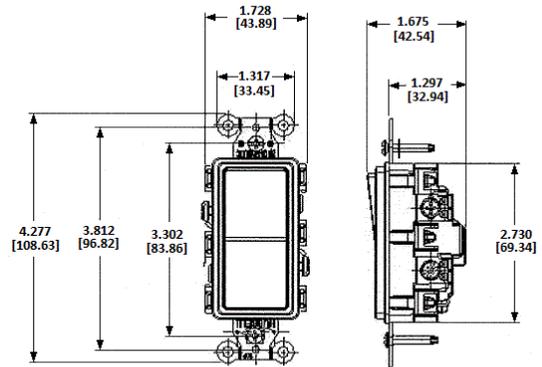

#### Online Resources

Customer Sales Drawings  
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

