

Straight Blade Devices

20A, 125V, 2 Pole, 3 Wire Grounding

USB Charger Receptacles

Features

- Two USB ports 3 Amp, 5V DC, type A, class 2.0
- Tamper-Resistant decorator duplex receptacle
- Green LED indicator to show USB power available
- Compatible with USB 1.1/2.0/3.0 devices, including Apple® products

Ordering Information

Description	Device Color	UPC Number	Catalog Number
SNAPConnect USB 20A 125V AC Charger, Tamper-Resistant Style Line® decorator duplex receptacle, two USB type 2.0 ports 3 Amp, 5 Volt DC	Ivory	883778305429	SNAP20USBI

Listings

UL1310 (SNAPConnect®)
cETLus listed to UL498


Specifications

Face	RTP
Base	RTP
LED	Green Indicator
Contacts	Plated Copper
Mounting Strap	Galvanized steel
Auto Self-grounding staple	Stainless steel
Mounting Screws	Zinc plated steel
USB Port	Stainless Steel

Performance

Electrical	
Current Interrupting	Receptacle certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Product Identification	Ratings are a permanent part of the device
Terminal Accommodation	#14-#10 AWG copper stranded or solid conductor only
Terminal Identification	Terminals identified in accordance with UL 498 and CSA
USB Port	Stainless steel Rated for 10,000 plug insertions and removal
Environmental	
Flammability	UL 94V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (w/o impact)

HUBBELL

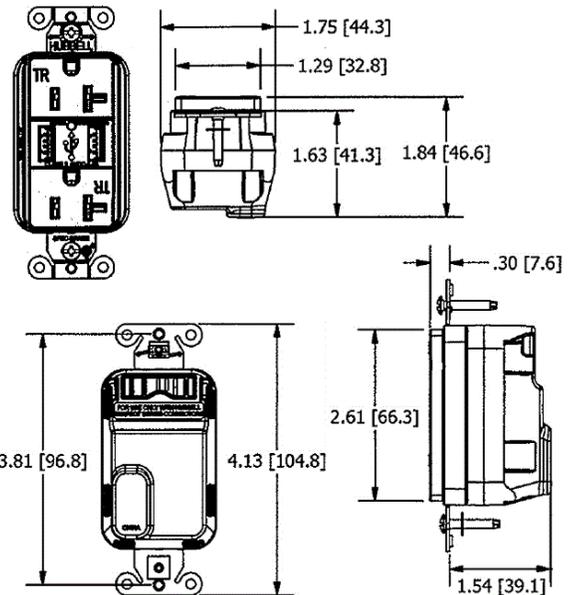

Online Resources

Customer Sales Drawing
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

