

Straight Blade Devices  
15A, 125V, 2 Pole, 3 Wire Grounding  
Extra Heavy Duty SNAPConnect®  
Receptacles

Features

- Green LED Power Indicators
- Aesthetic Style Line® decorator design
- Audible SNAP, indicates solid connection
- Reduces installation time
- Fully insulated design

Ordering Information

| Description                                                                 | Device Color | UPC          | Catalog Number |
|-----------------------------------------------------------------------------|--------------|--------------|----------------|
| Specification grade, with Power Indicating LED, Style Line® decorator face. | Black        | 783585248745 | SNAP2152BKL    |

Listings

UL Listed to UL498 File No. E2186  
Certified to CSA, C22.2, No. 42 File 285  
Fed. Spec. W-C-596  
NEMA® WD-6 Compliant


Specifications

|                            |                   |
|----------------------------|-------------------|
| Face                       | Nylon             |
| Base                       | PBT               |
| Contacts                   | Brass             |
| Mounting Strap             | Galvanized steel  |
| Auto Self-grounding Staple | Stainless steel   |
| Mounting Screws            | Zinc plated steel |

Performance

|                        |                                                                     |
|------------------------|---------------------------------------------------------------------|
| <b>Electrical</b>      |                                                                     |
| Current Interrupting   | Receptacle certified for current interrupting at full rated current |
| Dielectric Voltage     | Withstands 2,000V minimum                                           |
| <b>Mechanical</b>      |                                                                     |
| Product Identification | Ratings are a permanent part of the device                          |
| <b>Environmental</b>   |                                                                     |
| Flammability           | UL 94V-2                                                            |
| Operating Temperature  | Maximum continuous 75°C; minimum -40°C (without impact)             |

HUBBELL

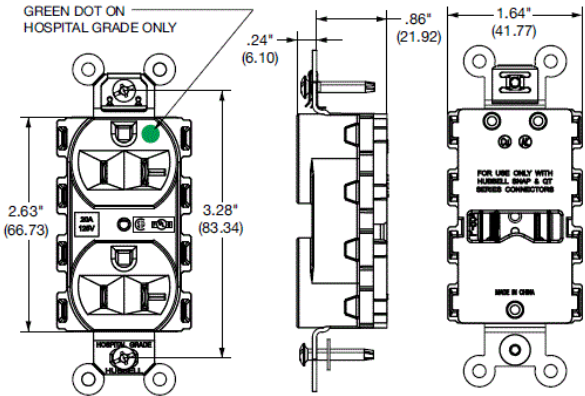

Accessories

Wallplate or Weatherproof Cover StyleLine® Decorator Opening

Resources

eCatalog

