

Straight Blade Devices

20 Amp, 125 Volt, 2-Pole, 3-Wire

SNAPConnect<sup>®</sup> Extra Heavy Duty Receptacle




- Features
- Audible SNAP, indicates solid connection
  - Reduces installation time
  - Requires minimal box space
  - Assembled in USA

| Ordering Information |              |              |                |
|----------------------|--------------|--------------|----------------|
| Description          | Device Color | UPC Number   | Catalog Number |
| Standard Duplex      | Lt Almond    | 783585540221 | SNAP2162LANA   |

- Listings
- UL Listed to UL498 File No. E2275  
Certified to CSA, C22.2, No. 42 File 374  
Fed. Spec. W-C-685  
NEMA<sup>®</sup> WD-6 Compliant

| Specifications |       |
|----------------|-------|
| Face           | Nylon |
| Base           | Nylon |
| Line Contact   | Brass |
| Ground Contact | Brass |

| Performance            |                                                          |
|------------------------|----------------------------------------------------------|
| <b>Electrical</b>      |                                                          |
| Current Interrupting   | Certified for current interrupting at full rated current |
| Dielectric Voltage     | Withstands 2,000V minimum                                |
| <b>Mechanical</b>      |                                                          |
| Product Identification | Ratings are a permanent part of the device               |
| <b>Environmental</b>   |                                                          |
| Flammability           | UL 94V-2                                                 |
| Operating Temperature  | Maximum continuous 75°C; minimum -40°C (without impact)  |

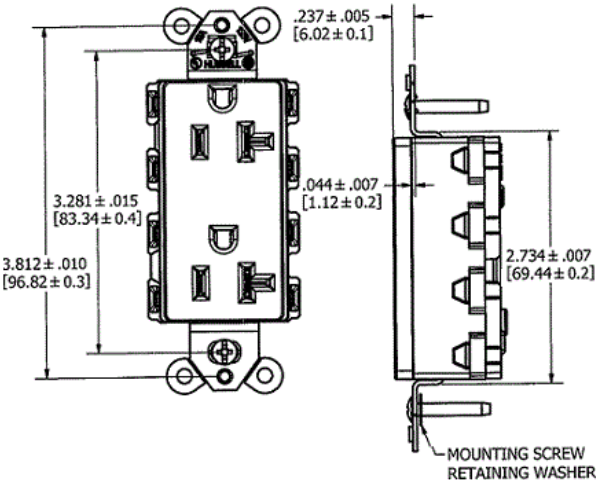

Complementary Products

Wallplate or Weatherproof Cover  
Opening

Online Resources

Customer Sales Drawing  
eCatalog  
Installation Instructions

