

# Straight Blade Devices 15A, 125V, 2 Pole, 3 Wire Grounding Extra Heavy Duty SNAPConnect® Receptacles

# HUBBELL

## Features

- Green LED Power Indicators
- Audible SNAP, indicates solid connection
- Reduces installation time
- Fully insulated design

## Ordering Information

Description	Device Color	UPC	Catalog Number
Specification grade, with Power Indicating LED, smooth face	Light Almond	783585193144	SNAP5262LAL

## Listings


UL Listed to UL498 File No. E2186  
 Certified to CSA, C22.2, No. 42 File 285  
 Fed. Spec. W-C-596  
 NEMA® WD-6 Compliant

## Specifications

Face	Nylon
Base	PBT
Contacts	Brass
Mounting Strap	Galvanized steel
Auto Self-grounding Staple	Stainless steel
Mounting Screws	Zinc plated steel

## Performance

Electrical	
Current Interrupting	Receptacle certified for current interrupting at full rated current with equivalently rated NEMA® plug
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Product Identification	Ratings are a permanent part of the device
Terminal Identification	Terminal wire leads identified in accordance with UL 498
Environmental	
Flammability	UL 94 V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (without impact)

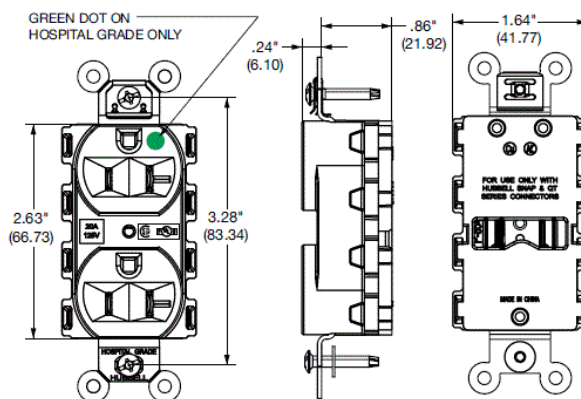

## Accessories

Wallplate or Weatherproof Cover Duplex Opening

## Resources

eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

