

Straight Blade Devices
15A, 125V, 2 Pole, 3 Wire Grounding
Extra Heavy Duty SNAPConnect®
Receptacles

Features

- Green LED Power Indicators
- Audible SNAP, indicates solid connection
- Reduces installation time
- Fully insulated design

Ordering Information

Description	Device Color	UPC	Catalog Number
Specification grade, with Power Indicating LED, smooth face	Red	783585193151	SNAP5262RL

Listings

UL Listed to UL498 File No. E2186
Certified to CSA, C22.2, No. 42 File 285
Fed. Spec. W-C-596
NEMA® WD-6 Compliant


Specifications

Face	Nylon
Base	PBT
Contacts	Brass
Mounting Strap	Galvanized steel
Auto Self-grounding Staple	Stainless steel
Mounting Screws	Zinc plated steel

Performance

Electrical	
Current Interrupting	Receptacle certified for current interrupting at full rated current with equivalently rated NEMA® plug
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Product Identification	Ratings are a permanent part of the device
Terminal Identification	Terminal wire leads identified in accordance with UL 498
Environmental	
Flammability	UL 94 V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (without impact)

HUBBELL

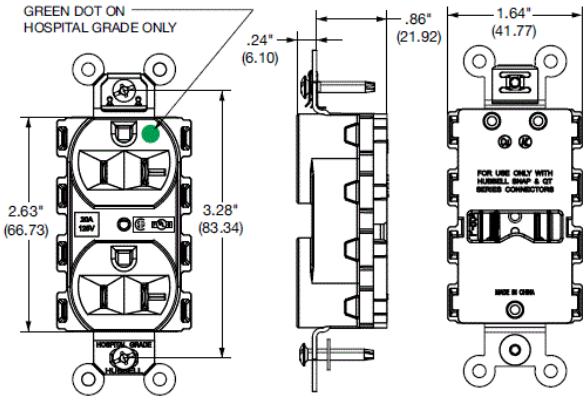

Accessories

Wallplate or Weatherproof Cover Duplex Opening

Resources

eCatalog

