

Straight Blade Devices

15 Amp, 125 Volt, 2-Pole, 3-Wire

SNAPConnect® Extra Heavy Duty Receptacle

HUBBELL

- Features
- Audible SNAP, indicates solid connection
 - Reduces installation time
 - Tamper-Resistant, Split Circuit
 - Assembled in USA


Description	Device Color	UPC Number	Catalog Number
Standard Duplex	Brown	783585552781	SNAP5262SCTRA

Listings

UL Listed to UL498 File No. E2406
Certified to CSA, C22.2, No. 42 File 505
Fed. Spec. W-C-816
NEMA® WD-6 Compliant

Specifications	
Face	Nylon
Base	Nylon
Line Contact	Brass
Ground Contact	Brass

Performance	
Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Product Identification	Ratings are a permanent part of the device
Environmental	
Flammability	UL 94V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (without impact)

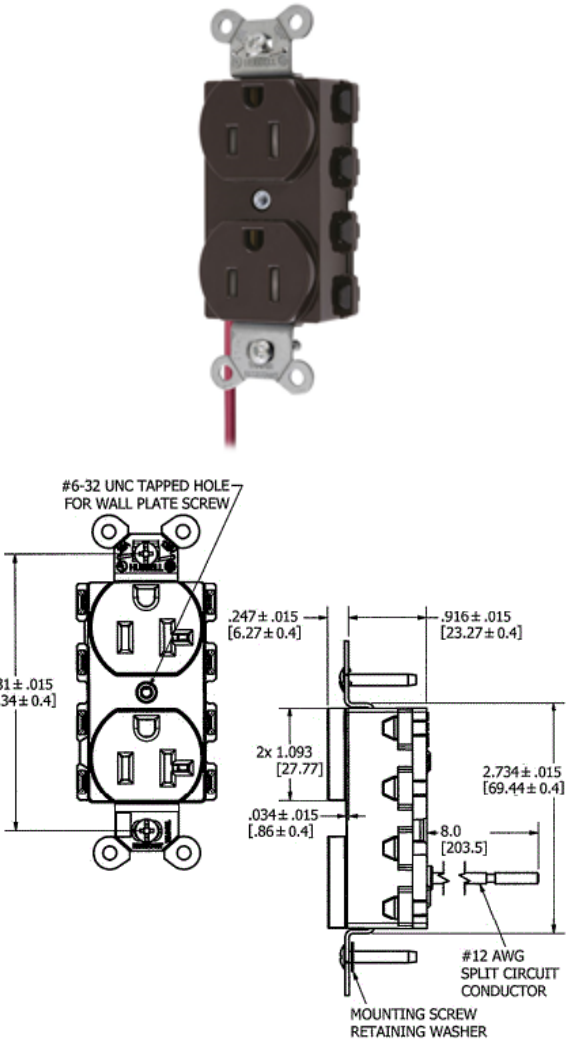

Complementary Products

Wallplate or Weatherproof Cover
Opening

Online Resources

Customer Sales Drawing
eCatalog
Installation Instructions

