

## Straight Blade Devices, Receptacles, Single, Commercial Grade, 2-Pole 3-Wire Grounding, 15A 125V, 5-15R, Orange, Single Pack

By Hubbell Wiring Device-Kellems  
Catalog # [SR15IG](#)

Straight Blade Devices, Receptacles, Single, Commercial Grade, 2-Pole 3-Wire Grounding, 15A 125V, 5-15R, Orange, Single Pack

### Features

- Receptacles
- Single
- Commercial Grade
- 2-Pole 3-Wire Grounding

### Application

Select-Spec Devices

### Specifications


Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	No
Nema Rating	5-15R

### Conductor

Number Of Wires	3-Wire Grounding
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

### Current

Phase	Single Phase
-------	--------------

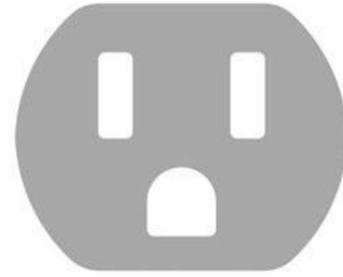

**Oh No!**  
IMAGE COMING SOON

Current / Amperage Rating	15 A
Connectivity	Screw Terminals
Current Rating	15 A
Amperage Rating	15 A
Wattage	1875
Voltage Rating	125 VAC

### Dimensions

Display Size	Standard Sized Product
--------------	------------------------

### General

Item Type	Single
Material - Mounting Hardware	Screw Mounting
OEM Brand Name	Hubbell Wiring Device-Kellems
Material	Thermoplastic
UPC	783585328898
Color	Orange

### Logistics

Carton Quantity	10
-----------------	----

### Product Assets

[Catalog \[English\]](#)