

Straight Blade Devices

15A, 125V, 2 Pole, 3 Wire Grounding

USB Charger Receptacles

Features

- Weather and Tamper Resistant Commercial Grade
- Combination Ports, One Type A, One Type C
- High Power 5 Amp, 5 Volt USB Output
- USB Ports Rated 10,000 Cycles
- Heavy Duty Spec Grade

Ordering Information

| Description | Color | UPC Number | Catalog Number |
|--|-------|------------|----------------|
| Weather and Tamper Resistant 15A/125V Duplex, 5 Amp, 5 Volts USB Ports | Ivory | | USB15AC5WR |

Listings

cULus Listed to UL498, UL1310
Complies with battery charging specification USB BC1.2
Compatible with USB 1.1/2.0/3.0 devices, including Apple® products
Meets Section 406.9 of the NEC making it suitable for outdoor use.


Specifications

| | |
|--------------------|--|
| Code Compliance | Complies with Part 15 of the FCC Rules |
| Electrical Ratings | 15 or 20 Amp, 125V AC |
| Port Rating | 5 Amp, 5 Volt |
| Indicator | Green LED |
| Contacts | Brass Triple-Wipe |
| Terminal Screws | Stainless Steel |
| Mounting Strap | Brass |
| Mounting Screws | Stainless Steel |
| USB Port | Stainless Steel |
| Auto-Ground Staple | Stainless Steel |

Performance

| | |
|-----------------------|--|
| Electrical | |
| Current Interrupting | Certified at full rated current |
| Dielectric Voltage | Withstands 1,500V minimum |
| Mechanical | |
| Operating Temperature | Maximum continuous 75°C, minimum -40°C (w/o impact) |
| Outdoor Suitability | UL 746C f1 |
| USB Ports | Stainless steel, rated for 10,000 charge-cable insertion cycles |
| Environmental | |
| Flammability | UL 94V-2 |
| Outdoor Suitability | UL 746C f1, Weather Resistant Device suitable for use outdoor with 3R extra duty protected enclosure, in compliance with NEC 406.9 |

HUBBELL

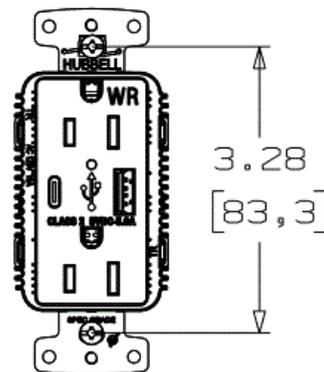

15A WEATHER RESISTANT
(WR) DEVICE

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

