

Straight Blade Devices

15A, 125V, 2 Pole, 3 Wire Grounding

USB Charger Receptacles

Features

- Weather and Tamper Resistant Commercial Grade
- Combination Ports, One Type A, One Type C
- High Power 5 Amp, 5 Volt USB Output
- USB Ports Rated 10,000 Cycles
- Heavy Duty Spec Grade

Ordering Information

Description	Color	UPC Number	Catalog Number
Weather and Tamper Resistant 15A/125V Duplex, 5 Amp, 5 Volts USB Ports	Light Almond		USB15AC5LAWR

Listings

cULus Listed to UL498, UL1310
Complies with battery charging specification USB BC1.2
Compatible with USB 1.1/2.0/3.0 devices, including Apple® products
Meets Section 406.9 of the NEC making it suitable for outdoor use.


Specifications

Code Compliance	Complies with Part 15 of the FCC Rules
Electrical Ratings	15 or 20 Amp, 125V AC
Port Rating	5 Amp, 5 Volt
Indicator	Green LED
Contacts	Brass Triple-Wipe
Terminal Screws	Stainless Steel
Mounting Strap	Brass
Mounting Screws	Stainless Steel
USB Port	Stainless Steel
Auto-Ground Staple	Stainless Steel

Performance

Electrical	
Current Interrupting	Certified at full rated current
Dielectric Voltage	Withstands 1,500V minimum
Mechanical	
Operating Temperature	Maximum continuous 75°C, minimum -40°C (w/o impact)
Outdoor Suitability	UL 746C f1
USB Ports	Stainless steel, rated for 10,000 charge-cable insertion cycles
Environmental	
Flammability	UL 94V-2
Outdoor Suitability	UL 746C f1, Weather Resistant Device suitable for use outdoor with 3R extra duty protected enclosure, in compliance with NEC 406.9

HUBBELL

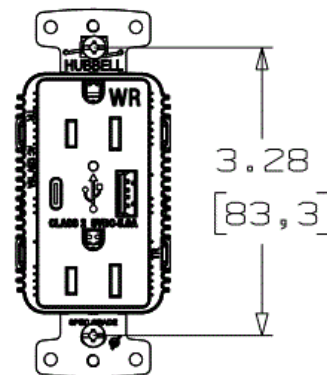

15A WEATHER RESISTANT
(WR) DEVICE

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

