


## 53mm Carboy Cap, Open Top, Two 1/4" & One 1/8" OD Tubes, 12" Length - 12893

### Product Images

---

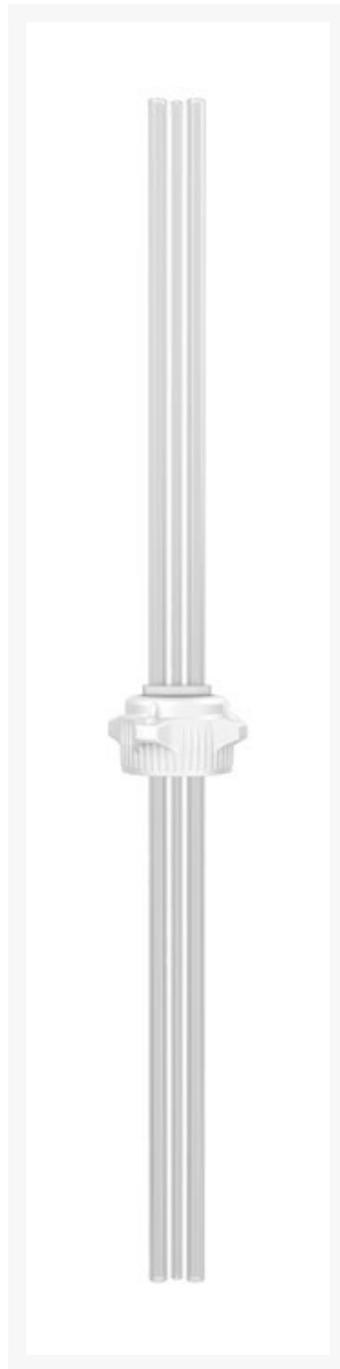

## Short Description

---

- Aseptic handling solutions for high purity fluids and sensitive biologicals
- Eliminate open-air pouring of high valued products with this leak proof, closed system
- High purity platinum-cured silicone insert with or without tubing

## Description

---

- Eliminate open-air pouring of high valued products with this leak proof, closed system
- High purity platinum-cured silicone insert with or without tubing

Designed for aseptic fluid transfer, sampling, or sealing of high purity fluids and sensitive biologicals in pharmaceutical and laboratory applications, these systems features a platinum-cured silicone insert, with or without silicone tubing, and a polypropylene cap that fits bottles or carboys with 53-mm, 83-mm, or 120-mm closures. All components can be autoclaved at 15 PSI and 250°F (121°C) for 20 minutes.

Note: Height includes pre-mounted tubing.

## Specifications

---

Model No	12893
UPC	697841181182
International Model No.	12893
Material Specifications	Polypropylene
Dimensions, Exterior	24.7" H x 3" Outer Dia. 627mm H x 76mm Outer Dia.
Net Weight, lbs	0.8
Net Weight, kg	0.4