


83mm Carboy Cap With Two 1/4" and One 3/8" OD Tubes, 27" Length, Open Top - 12896

Product Images

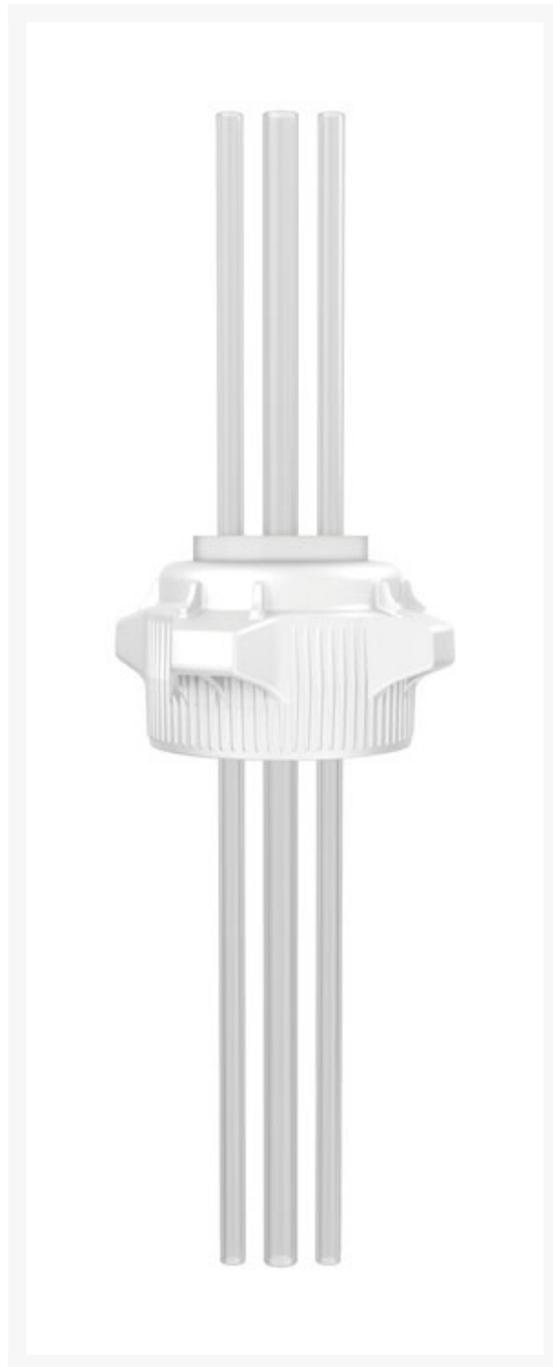

Short Description

- Aseptic handling solutions for high purity fluids and sensitive biologicals
- Eliminate open-air pouring of high valued products with this leak proof, closed system
- High purity platinum-cured silicone insert with or without tubing

Description

- Eliminate open-air pouring of high valued products with this leak proof, closed system
- High purity platinum-cured silicone insert with or without tubing

Designed for aseptic fluid transfer, sampling, or sealing of high purity fluids and sensitive biologicals in pharmaceutical and laboratory applications, these systems features a platinum-cured silicone insert, with or without silicone tubing, and a polypropylene cap that fits bottles or carboys with 53-mm, 83-mm, or 120-mm closures. All components can be autoclaved at 15 PSI and 250°F (121°C) for 20 minutes.

Note: Height includes pre-mounted tubing.

Specifications

Model No	12896
UPC	697841181212
International Model No.	12896
Material Specifications	Polypropylene
Dimensions, Exterior	45.9" H x 5" Outer Dia. 1166mm H x 127mm Outer Dia.
Net Weight, lbs	1.0
Net Weight, kg	0.5