


10' x 11' x 2", 135 Gallon Spill Capacity, Maintenance Spill Berm, Yellow - 28424

Product Images

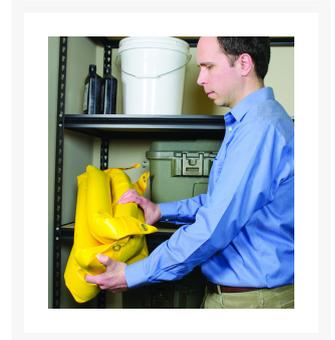

Short Description

- Compact and flexible spill containment deploys instantly in the shop or field
- No assembly required—simply unfold and use
- Encased urethane foam sidewalls offer easy roll-through access without the need for a ramp
- Walls quickly spring back into place with no memory loss
- Helps comply with EPA SPCC regulations

Description

Quickly contain minor spills and leaks during temporary storage of drums, machine parts, batteries, and equipment. Lightweight EnGuard™, PVC coated fabric provides broad UV and chemical resistance. Anchor

berm in place using the brass grommets in each corner. Anchor stakes not included. Order optional grates to keep products and machinery above fluid.

Helps comply with EPA for spill prevention (SPCC).

Specifications

Model No	28424
Special Price Type	Sale
UPC	697841157095
International Model No.	28424
Color	Yellow
Material Specifications	PVC Coated Fabric
EPA Compliance	Helps comply with EPA for spill prevention (SPCC)
Capacity	135 gallon
Liter Capacity	511
Dimensions, Exterior	126" W x 2" H x 138" L
	3200mm W x 51mm H x 3505mm L
Dimensions, Interior	120" W x 2" H x 132" L
	3048mm W x 51mm H x 3353mm L
Dimensions, Folded	28" W x 16" H x 28" L
	711mm W x 406mm H x 711mm L
Net Weight, lbs	27.0
Net Weight, kg	12.2