


## Steel Gas Cylinder Support Bracket, Two 12" Cylinder Capacity, Bench Mount - 35270

### Product Images

---

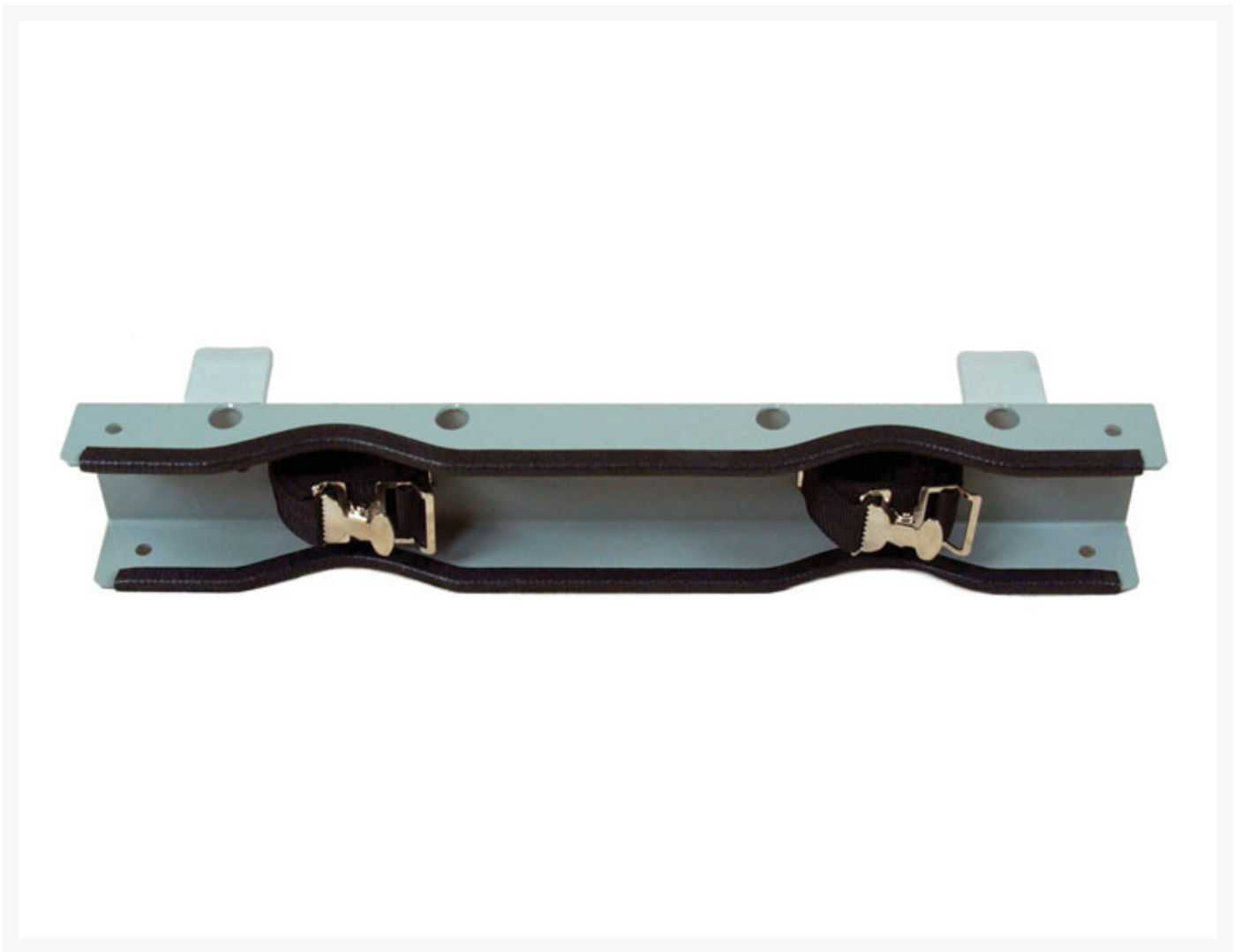

### Short Description

---

- Brackets accept cylinder sizes ranging from 4- to 12-in (102- to 305-mm)
- Exclusive bumper guard edging with steel reinforced vinyl protects your cylinders from damage while providing extra grip
- Designed for bench mounting applications

## Description

---

Cylinder support brackets provide a quick and easy solution for storing gas cylinders when space is at premium. Constructed from heavy gauge, powder-coated steel to ensure long service life and chemical resistance. Using dual 0.375-in (10-mm) diameter clamping posts with 1.5-in (38-mm) swivel pad faces, these models clamp to tables 1- to 2.75-in (26- to 70-mm) thick. Heavy-duty polypropylene support straps, 1.5- x 54-in (38-mm x 1372-mm) and rated at 1138-lb (516-kg), feature steel cinch buckle and hold individual cylinders securely against bracket. For an improved level of safety for any installation, all brackets include openings to retrofit secondary support chains, one set for each cylinder station.

Helps comply with OSHA, NFP1, NFPA 55, and CGA.

## Specifications

---

|                                         |                                    |
|-----------------------------------------|------------------------------------|
| Model No                                | 35270                              |
| UPC                                     | 697841210912                       |
| Cylinder Capacity                       | 2                                  |
| Minimum Cylinder Diam (in)              | 4                                  |
| Cylinder Capacity with Max Cylinder Dia | (2) 12 inch                        |
| Mount Type                              | Wall                               |
| Strap Style                             | Poly Cinch Strap with Steel Buckle |
| Straps Per Cylinder                     | 1                                  |
| Material Specifications                 | Steel                              |
| Complies with NFPA 1 Fire-Code          | Yes                                |
| NFPA 55                                 | Yes                                |
| OSHA Compliance                         | Yes                                |
| CGA                                     | Yes                                |
| Net Weight, lbs                         | 9                                  |
| Net Weight, kg                          | 4                                  |
| Net Dimensions (W x D x H)              | 23.75 x 4 x 4.25 inches            |
|                                         | 603 x 102 x 108 mm                 |