


Medical Oxygen Cylinder Stand, One 5.75 to 6.75" Diameter Cylinder Capacity - 35328

Product Images

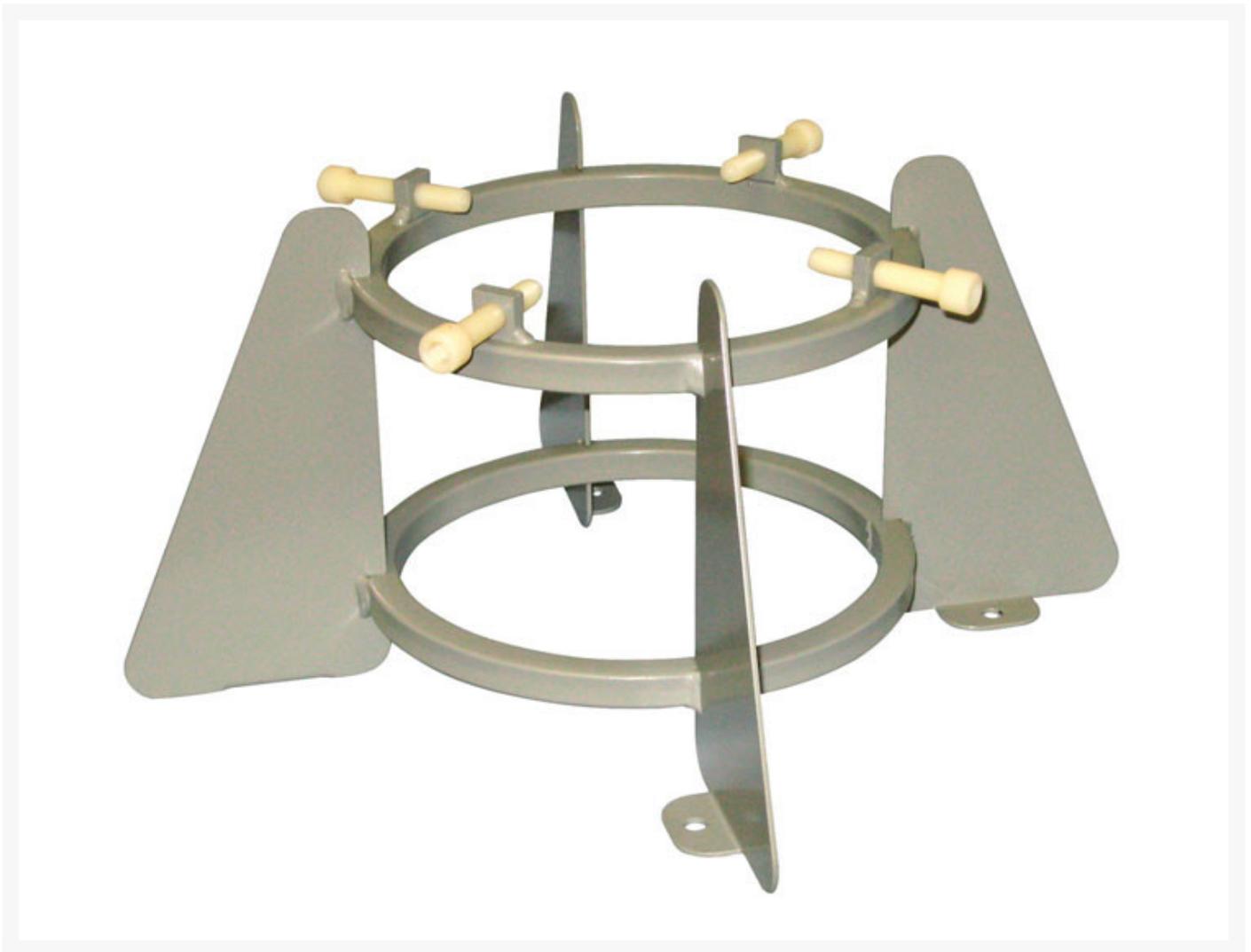

Short Description

- One Cylinder Capacity
- Corrosion-resistant coating
- Pre-drilled Mounting holes

Description

Commonly used for medical oxygen or calibration gases in laboratories, this ring stand uses 0.375-in (10-mm) nylon set screws to hold cylinders from 5.75- to 6.75-in (146- to 172-mm) in place. Constructed using steel with corrosion-resistant powder coating, the stands include mounting holes for permanent installations.

Helps comply with OSHA, NFP1, NFPA 55, and CGA.

Specifications

Model No	35328
UPC	697841211193
Cylinder Capacity	1
Minimum Cylinder Diam (in)	5.75
Cylinder Capacity with Max Cylinder Dia	(1) 6.75 inch
Mount Type	Bench
Mount Holes	3
Mount Hole Size (inch)	0.312
Material Specifications	Steel
Net Weight, lbs	7
Net Weight, kg	3
Net Dimensions (W x D x H)	14.5 x 14.5 x 7 inches
	368 x 368 x 178 mm