





17 Gallon, 1 Shelf, 2 Doors, Manual Close, Wall Mount Flammable Cabinet, Sure-Grip® EX, Yellow - 8917008

Product Images

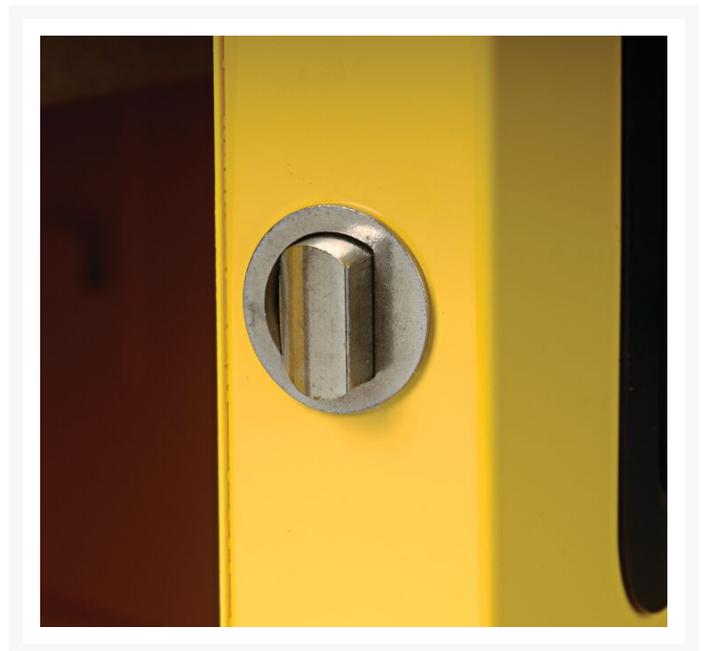

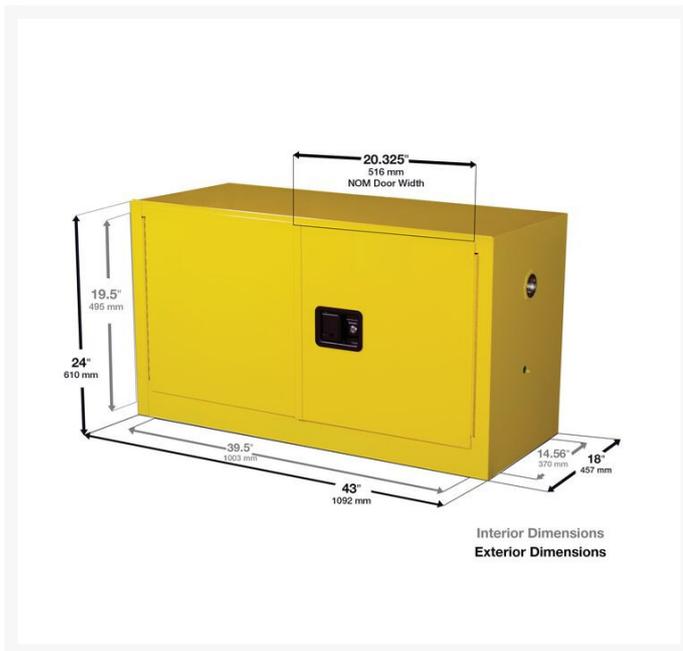

Short Description

- Hang cabinet above workbench for easy access
- Protect workers
- Reduce fire risks
- Meet safety codes
- Ten-year warranty

Description

Gain storage space near work areas without taking up extra floor space. Eye-level positioning allows for easy access to solvents. Model 8917008 features one adjustable shelf to accommodate multiple containers. Cabinet comes complete with mounting hardware. This cabinets have all the great features and benefits of our classic cabinets as outlined below.

Protect workers, reduce fire risks, and improve productivity by storing flammable fuels and chemicals in code-compliant safety cabinets. Designed to meet OSHA and NFPA standards, Sure-Grip® EX cabinets are constructed of sturdy 18-gauge (1-mm) thick double-wall, welded steel with 1-1/2" (38-mm) of insulating air space for fire resistance. High-performance, manual-close, self-latching doors open to a full 180 degrees and close easily and securely for maximum protection under fire conditions when pushed shut. Fail-safe closing mechanism ensures three-point stainless steel bullet latching system works every time.

For added security, U-Loc™ handle comes with a cylinder lock and key set or accepts an optional padlock. Haz-Alert™ reflective warning labels are highly visible under fire conditions or during power outages when illuminated with a flashlight.

Patented SpillSlope® galvanized steel shelves direct spills to back and bottom of a leakproof 2" (51-mm) bottom sump. They adjust on 3" (76-mm) centers for versatile storage. Cabinets also feature dual vents with

flame arresters, four adjustable self-leveling feet, grounding connector, and trilingual warning label. Durable lead-free epoxy/polyester powder-coat finish provides excellent chemical resistance.

All cabinets come with a ten-year warranty.

Specifications

Model No	8917008
UPC	697841119413
International Model No.	8917008
Color	Yellow
Material Specifications	18-Gauge Steel
OSHA Compliance	Yes
Complies with NFPA Code 30	Yes
Capacity	17 gallon
Liter Capacity	64
Number of Doors	2
Door Type	Manual
Number of Shelves	1
Adjustable Shelves	Yes
Dimensions, Exterior	24" H x 43" W x 18" D
	610mm H x 1092mm W x 457mm D
Dimensions, Interior	19.5" H x 39.5" W x 14.6" D
	495mm H x 1003mm W x 370mm D
Height (Inches)	24
Width (Inches)	43
Depth	18
Net Weight, lbs	131.0
Net Weight, kg	59.4