





# 22 Gallon, 1 Shelf, 2 Doors, Self Close, Flammable Cabinet, Sure-Grip® EX Under Counter, White - 892325

## Product Images

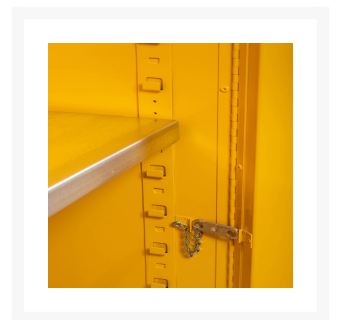

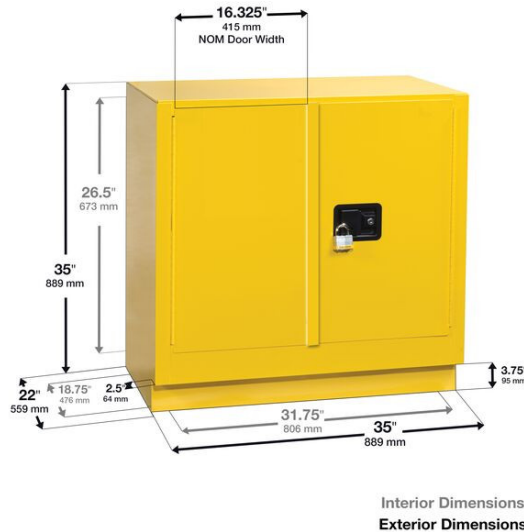

## Short Description

- Designed for the safe storage of chemicals and flammable liquids beneath countertops and work benches
- Exterior dimensions of 35 in x 35 in x 22 in (889 mm x 889 mm x 559 mm)
- Storage capacity of 22 gallons (83 liters) of flammable liquids
- Recessed toe kick improves ergonomics and mounts flush with other cabinets
- Complies with OSHA, NFPA 30, NFPA 1 and IFC
- Fire tested and FM-approved

## Description

Conveniently locate flammable liquids near work areas, with the Justrite Sure-Grip® Undercounter Safety Cabinet with Self Close Doors (model 892325). It can be safely placed beneath countertops and work benches and features a 3.5 in H x 2.2 in D (89 mm H x 64 mm D) recessed toe kick. This allows users to stand closer to the work surface, which means less leaning and better ergonomics.

With exterior dimensions of 35 in x 35 in x 22 in (889 mm x 889 mm x 559 mm), this white cabinet can store 22 gal (83 L) of flammable liquids.

This model is constructed with a sturdy 18-gauge (1-mm) thick steel double-wall, with 1.5 in (38 mm) of insulating air space for fire resistance. The fully welded, not riveted, construction holds the squareness of the unit for a longer life and offers greater protection in a fire since air gaps are reduced.

High-performance, self-closing doors open to 140 degrees. A patented, concealed self-close mechanism provides obstruction-free access to shelf space. The doors self-index to guarantee they will close in tight

sequence. Continuous piano hinges ensure the doors close smoothly every time.

When used properly as designed, safety cabinets with self-closing doors shut automatically in case of a fire. The self-closing doors, under tension, are held open by using fusible links. Under fire conditions, when the ambient temperature reaches 165 F (74 C), the links melt and the safety cabinet's self-closing doors automatically swing shut. The self-latching system engages with three stainless steel bullet-slams located at the top, bottom, and center locations of the door. For replacement fusible links, order model 29988.

For added security, each cabinet comes with an innovative U-Loc™ handle that does not require manual rotation to engage the mandatory latch. Cabinets include a cylinder lock and key set, or you can choose to use your own padlock. Trilingual Haz-Alert™ reflective warning labels that read "FLAMMABLE – KEEP FIRE AWAY" are highly visible under fire conditions or during power outages when illuminated with a flashlight.

Model 892325 features one patented, galvanized steel SpillSlope® shelf designed to direct spills to the back and bottom into a 2-in (51-mm) leak-tested sump that meets EPA requirements. Adjustable on 3-in (76-mm) centers, all SpillSlope shelves meet ANSI MH28.1 standards with a 350-lb (159-kg) safe allowable load. Welded shelf hangers interlock with the shelf to offer maximum stability with no flimsy brackets to lose. For a replacement shelf, use model 29939.

The cabinet also features dual vents with flame arresters, four adjustable self-leveling feet that adjust to 1.125 in (29 mm) for alignment on uneven floors, and a built-in grounding connector. Its durable lead-free epoxy/polyester powder-coat finish provides excellent chemical resistance inside and out, as well as minimizes the effects of corrosion and humidity.

Justrite supplies more than 300 safety cabinet models ranging from 4- to 115-gal (15- to 435-L), to meet a versatile range of safety, compliance, and storage requirements.

All Justrite cabinets carry a 10-year warranty. Model 892325 is tested and approved by FM Approvals. It complies with OSHA, NFPA 30, NFPA 1, and IFC requirements.

## Safety Considerations for Undercounter Safety Cabinets

The requirements for handling and storing chemicals are complex and depend on how flammable the liquid is. There is no room for error, so it is critical to choose a safety cabinet that has been independently tested to meet the standards of your industry and local jurisdictions. Not just any safety cabinet will do. Justrite flammable cabinets are best in class and are trusted within a wide range of industrial settings across the world, including laboratories, manufacturing, oil refineries, chemical processing plants, and more.

For more information, please consult our workplace safety article about the [requirements for flammable liquid storage](#).

## Specifications

|                                       |                             |
|---------------------------------------|-----------------------------|
| Model No                              | 892325                      |
| UPC                                   | 697841113244                |
| International Model No.               | 8923251                     |
| Color                                 | white                       |
| Material Specifications               | 18-Gauge Steel              |
| FM Approval                           | Yes                         |
| OSHA Compliance                       | Yes                         |
| Complies with International Fire Code | Yes                         |
| Complies with NFPA Code 30            | Yes                         |
| Complies with NFPA 1 Fire-Code        | Yes                         |
| Capacity                              | 22 gallon                   |
| Liter Capacity                        | 83                          |
| Number of Doors                       | 2                           |
| Door Type                             | Self-close                  |
| Number of Shelves                     | 1                           |
| Adjustable Shelves                    | Yes                         |
| Dimensions, Exterior                  | 35" H x 35" W x 22" D       |
|                                       | 889mm H x 889mm W x 559mm D |
| Dimensions, Interior                  | 27.4" H x 31.8" W x 18.8" D |
|                                       | 695mm H x 806mm W x 476mm D |
| Height (Inches)                       | 35                          |
| Width (Inches)                        | 35                          |
| Depth                                 | 22                          |
| Net Weight, lbs                       | 152.0                       |
| Net Weight, kg                        | 68.9                        |