




# 54 Gallon, 3 Shelves, 1 Door, Manual Close, Corrosives/Acid Steel Safety Cabinet, Sure-Grip® EX Deep Slimline, Blue - 895402

## Product Images

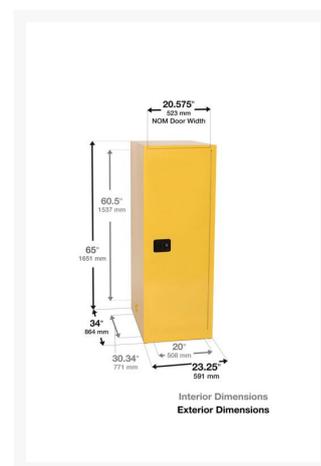

## Short Description

- Ideal for areas with limited floor space or to expand current storage conditions
- Offer same quality safety features as cabinets for flammables
- FM-approved
- Ten-year warranty

## Description

---

Research environments using many different types of chemicals have special storage requirements. Whether using acids, bases or solvents, it is critical that incompatible liquids are segregated to avoid disastrous explosions or fire. The SDS (Safety Data Sheet) should be reviewed to determine chemical characteristics and recommended storage practices.

Justrite blue steel Deep Slimline safety cabinets for corrosives have the same quality safety features as the cabinets for flammables. All models come with double-wall construction, dual vents, grounding wire connections, adjustable shelves, leakproof sills, three-point self-latching doors and leveling feet. Manual-close door(s) opens to a full 180 degrees and self-latches when pushed closed.

Additionally, they include polyethylene trays attached to galvanized steel shelves and a separate polyethylene liner for the bottom sump resist aggressive chemicals. Easily remove the liner for quick cleaning of drips and leaks. An all epoxy baked-on powder-coat finish, inside and out, provides increased chemical resistance.

Manual close models meet OSHA and NFPA 30. Cabinets are FM approved and come with a ten-year warranty.

## Specifications

---

Model No	895402
UPC	697841114081
International Model No.	8954021
Color	Blue
Material Specifications	18-Gauge Steel
FM Approval	Yes
OSHA Compliance	Yes
Complies with NFPA Code 30	Yes
Capacity	54 gallon
Liter Capacity	204
Number of Doors	1
Door Type	Manual
Number of Shelves	3
Adjustable Shelves	Yes
Dimensions, Exterior	65" H x 23.25" W x 34" D
	1651mm H x 591mm W x 864mm D
Dimensions, Interior	60.5" H x 20" W x 30.3" D
	1537mm H x 508mm W x 771mm D
Height (Inches)	65
Width (Inches)	23.25
Depth	34
Net Weight, lbs	262.0
Net Weight, kg	118.8