




# 110 Gallon, 2 Drum Vertical, 1 Shelf, 2 Doors, Manual Close, Flammable Cabinet With Drum Rollers, Sure-Grip® EX, Yellow - 899160

## Product Images

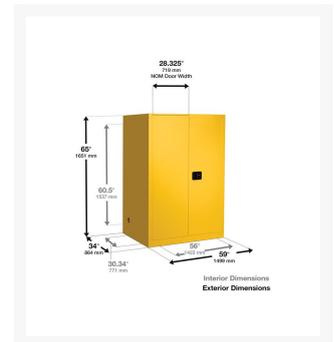



## Short Description

---

- Safely store solvent filled drums
- Available in many styles and sizes
- Manual-close or self-close doors
- Complies with OSHA regulations
- Custom safety cabinets available, [get a quote here](#)

## Description

---

For storage of larger quantities of flammable solvents, the heavy-duty Drum Safety Cabinet is available in many styles and sizes. Built to the same high standards as the smaller Classic Safety Cabinets, a reinforced liquid-tight sump contains spills. An array of drum accessories and equipment is available to ensure safety and convenience when storing and handling drums of hazardous materials.

Use these vertical drum safety cabinets to safely store 30- to 55-gallon (110- to 200-L) drums. The removable, adjustable, half-depth shelf provides enough head space to accommodate a drum with a pump or funnel so the cabinet can be used as a pumping or waste accumulation station, and also allows you to store Class III materials or spare accessories. Available with or without roller assemblies to easily move heavy drums. Complies with OSHA regulations.

Looking for a custom safety cabinet? [Request a quote here](#) for your storage requirements.

## Specifications

---

|                            |                               |
|----------------------------|-------------------------------|
| Model No                   | 899160                        |
| UPC                        | 697841115095                  |
| International Model No.    | 8991601                       |
| Color                      | Yellow                        |
| Pallet Quantity            | 1                             |
| Material Specifications    | 18-Gauge Steel                |
| OSHA Compliance            | Yes                           |
| Complies with NFPA Code 30 | Yes                           |
| Capacity                   | 110 gallon                    |
| Liter Capacity             | 400                           |
| Number of Doors            | 2                             |
| Door Type                  | Manual                        |
| Number of Shelves          | 1                             |
| Adjustable Shelves         | Yes                           |
| Dimensions, Exterior       | 65" H x 59" W x 34" D         |
|                            | 1651mm H x 1499mm W x 864mm D |
| Dimensions, Interior       | 60.5" H x 56" W x 30.3" D     |
|                            | 1537mm H x 1422mm W x 771mm D |
| Height (Inches)            | 65                            |
| Width (Inches)             | 59                            |
| Depth                      | 34                            |
| Net Weight, lbs            | 601.0                         |
| Net Weight, kg             | 272.6                         |